

Eya series



Ordering number C11469
Description C11469-Eya-S

Family Eya
Type lens
LED Platinum Dragon
Color
Diameter mm
Height mm
Style round
Optic Material PMMA
Holder Material
Fastening 1149
Status ready

Viewing Angle 0
Beam Type
Efficiency 0
cd/lm 0 mm




Ordering number CA11956
Description CA11956-Eya-S

Family Eya
Type lens
LED Platinum Dragon
Color black
Diameter 30,4 mm
Height 29,1 mm
Style round
Optic Material PMMA
Holder Material PC
Fastening 1310
Status ready


Viewing Angle 7
Beam Type
Efficiency 0
cd/lm 0 mm

D C B A

4

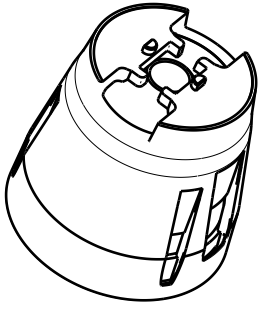


Isometric view

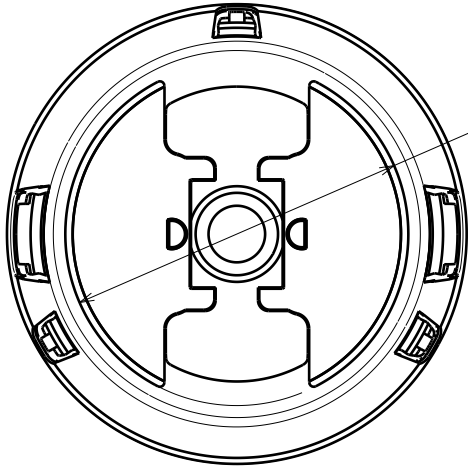

$\phi 22.7$
Bottom view

3

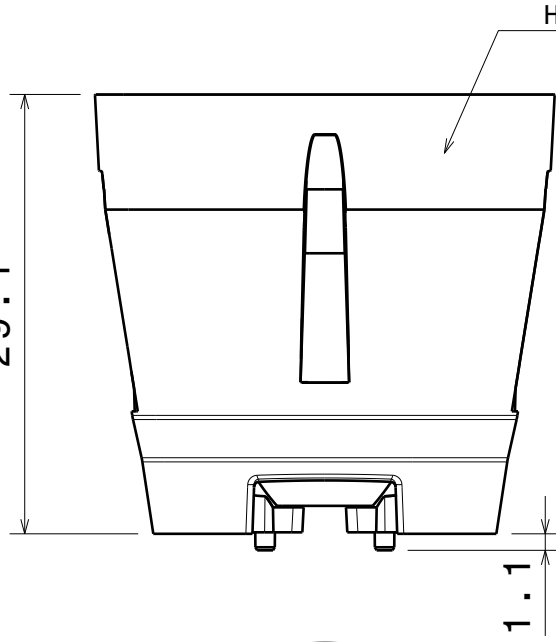


Holder
29.1
1.1
Front view

2


Part no.s:
CA11337_Eya-0
CA11956_Eya-S

Materials:
Lens PMMA
Holder PC, Black

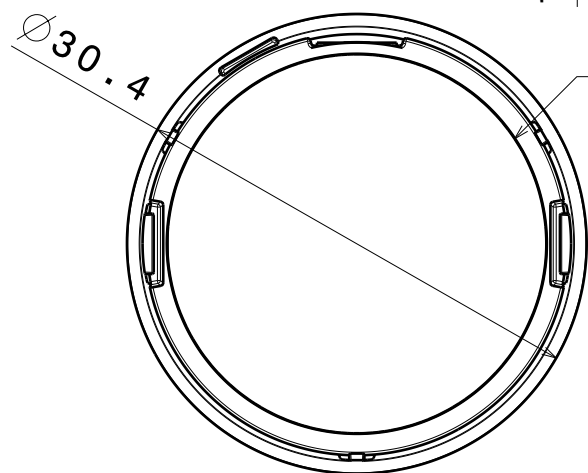

Lens
 $\phi 30.4$
Top view

This drawing is our property.
It can't be reproduced
or communicated without
our written agreement.

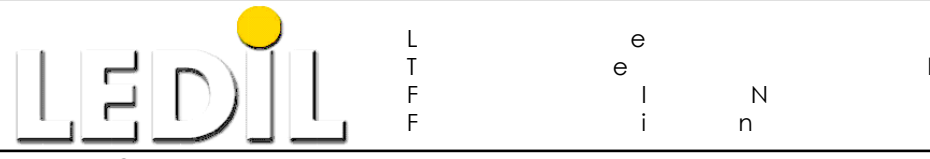

1

DRAWN BY p v		DATE 29.03.2011	DRAWING TITLE Datasheet Eya series assy			
CHECKED BY p		DATE 29.03.2011	SIZE A4	DRAWING NUMBER -		REV 1.0
DESIGNED BY pv		DATE 17.02.2011	SCALE 2 : 1	WEIGHT (g)		SHEET 1 / 1

D A