

Features

- 8mm cutout
- IP67 rating
- Amber
- LED illuminates at 12 & 24V
- Robust and stylish
- Fitted with leads

RS PRO 8mm Panel Indicator Light 12-24V Amber LED, IP67

RS Stock No.: 0325311



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


This range of small panel indicator lights are IP67 rated. The bright LED lamp will illuminate at both 12V and 24V. The stainless steel surround supports a domed indicator which looks highly attractive when mounted within a panel. These products are fitted with 150mm leads and the panel cut out is 8mm.
Colour Options: Red, Green, Orange or Blue.

These pilot lights are used within applications to show when a device or process is in operation. Applications are varied and include industrial control panels, medical, test & measurement, power distribution, security and access, home appliances and HVAC equipment.

Electrical Specifications



Specifications

Terminal type	150mm wire leads, 24AWG
LED	12-24VAC/DC Amber
Rated current	Between 2-5mA
Panel cut out	8mm
LED life	About 40,000 hours
Insulation resistance	$\geq 1000\text{M}\Omega(500\text{VDC})$ 1500V
Dielectric strength	RMS 50Hz 1 minute -25°C~
Operating temperature	+55°C
IP degree	IP67
Dropping way	6-24V Inner resistance
Materials: Body	Stainless steel
Base	PA
Head	EP


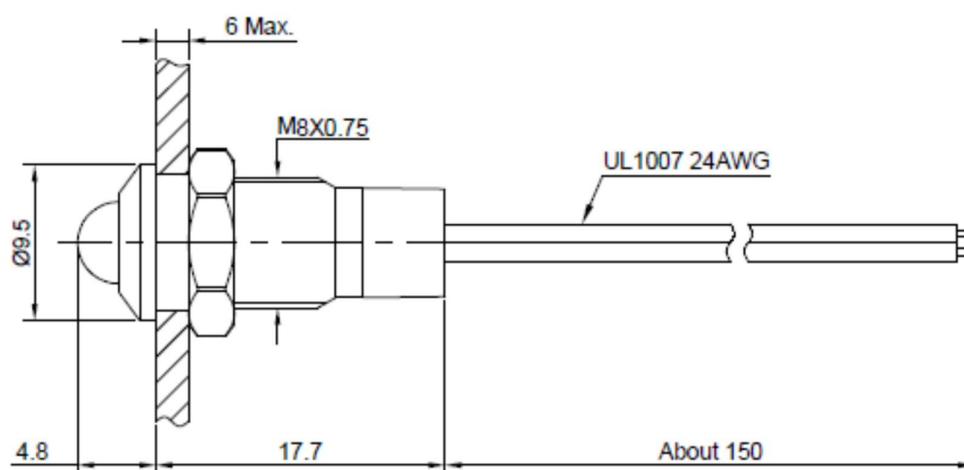


THE SHADED PART IS ILLUMINATED

  DIAGRAM



SEAL RING

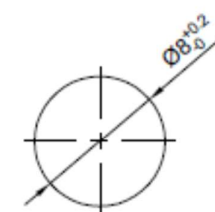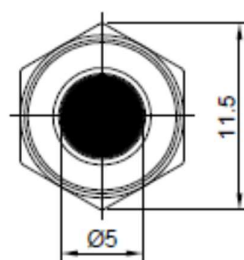

PANEL CUTOUT

ROHS Compliant