


issuDOM - CP100

Cross-bars - 1 point



Technical features

Type of mounting	Rim lock
Number of locking points	1
Application	Aluminium, steel, wooden doors, PVC profiles, emergency exit doors, doors for heavy traffic areas
Reversible	Yes
Fire resistant	Yes
Outside opening	Knob or handle
Bar dimension	1150 mm
Bar material	Aluminium
Bar finish	Lacquered
Material of the cases	Steel/zamak
Protection	Anti-corrosion treatment
Certifications and Standards	Certified EN 1125: 2008 Level 7 (max.) Certifire Certification
Durability test	More than 200 000 cycles opening/closing
Supplied accessories	Strike plate, screws, cover plate
On request	950 and 1450 mm bar dimensions

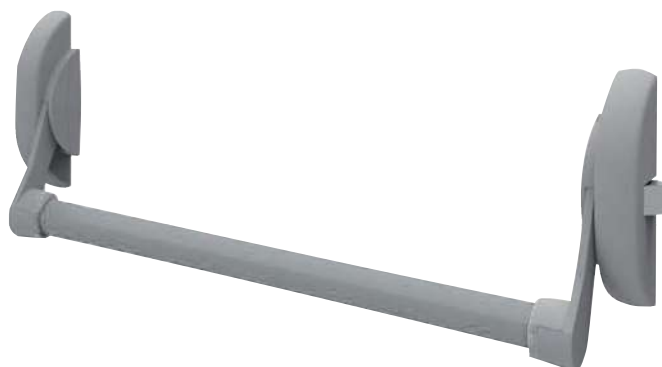

Logistics



≈ 3,400 kg



Individual box



Design
Fire-resistant as standard
Easy-fitting
Reduced size of case
Reversible without disassembling

Additional products



Exit pad



Exterior accessories with knob or handle



Adaptation kit

issuDOM - CP100

Cross-bars - 1 point



BAR DIMENSION	FINISH	ARTICLE NUMBER
1150	White RAL 9016	F2CR1PT0006
1150	Aluminium tone RAL 9006	F2CR1PT0005
1150	Black RAL 9005	F2CR1PT0004
Dimensions in mm		

