



iM2700

Storm

The Peli™ Storm Case™ has the same legendary DNA as our Peli Protector Case, with one primary difference: A unique Press and Pull latch that locks automatically, but open with a light touch.

Guaranteed for life, the Peli Storm case is made in the USA and engineered using the finest components.

- **Watertight, crushproof, and dustproof**

- Four Press & Pull Latches
- Two Padlockable Hasps
- Double-layered, Soft-grip Handle
- Vortex™ Valve
- Powerful Hinges
- Lightweight Strong HPX® Resin



CONFIGURATIONS



iM2700
Standard



iM2700-X0000
No Foam



iM2700-X0002
With Padded Dividers



iM2700-X0001
With Foam

DIMENSIONS

Interior (L×W×D)	22.00 x 17.00" x 8.00 (55.9 x 43.2 x 20.3 cm)
Exterior (L×W×D)	24.60 x 19.70" x 8.60 (62.5 x 50 x 21.8 cm)
Lid Depth	2.00" (5.1 cm)
Bottom Depth	6.00" (15.2 cm)
Total Depth	8" (20.3 cm)
Int Volume	1.73 ft ³ (0.049 m ³)
Padlock Hole Diameter	0.31" (0.8 cm)

MATERIALS

Body	Injection Molded HPX™ high performance resin
Latch	Valox - Polybutylene Terephthalate (PBT)
Latch (Alt)	Xenoy - Polyester/Polycarbonate blend
O-Ring	EPDM
Pins	Stainless Steel
Pins (Alt)	Aluminum
Foam	1.3/1.35 polyester
Purge Body	Valox - Polybutylene Terephthalate (PBT)
Purge Body (Alt)	Xenoy - Polyester/Polycarbonate blend
Purge Vent	Gortex membrane

COLOURS

 Black	 OD Green	 Yellow
---	--	--

WEIGHT

Weight With Foam	14.40 lbs (6.53 kg)
Weight Empty	11.10 lbs (5.03 kg)
Buoyancy	112.58 lbs (51.07 kg)
Master Pack Weight	30.00 lbs (13.61 kg)

TEMPERATURE

Minimum Temperature	-20°F (-28.9 °C)
Maximum Temperature	140°F (60 °C)

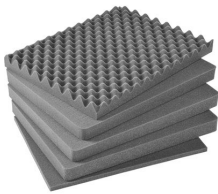
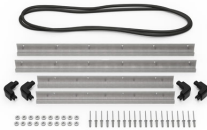
CERTIFICATIONS

IP67	
-------------	--

OTHER

Master Pack	2
Military	yes

ACCESSORIES

				
iM27XX-UTILITYORG Utility Organizer	iM2700-FOAM 5 pc. Replacement Foam Set	iM2700-DIV Padded Divider Set	iM-STRAP-S-VER2 Padded Shoulder Strap	iM-LIDSTAY Lid Stay
				
iM2700-M4-BEZEL Base Bezel Kit (Metric)	iM2700-M4-BEZEL-L Lid Bezel Kit (Metric)	1506TSA TSA Lock	1500D Desiccant Silica Gel	