

863001061TLF - D-
subminiature : Female screw
lock





www.fci.com

Specifications

General	
Packaging	Bulk
Product Type	Screw lock
Physical	
Material (Housing)	Metal
Material (Characteristics)	Brass
Other Features	
Most Popular Configuration	Yes
Pack factor	100



Copyright FCI.

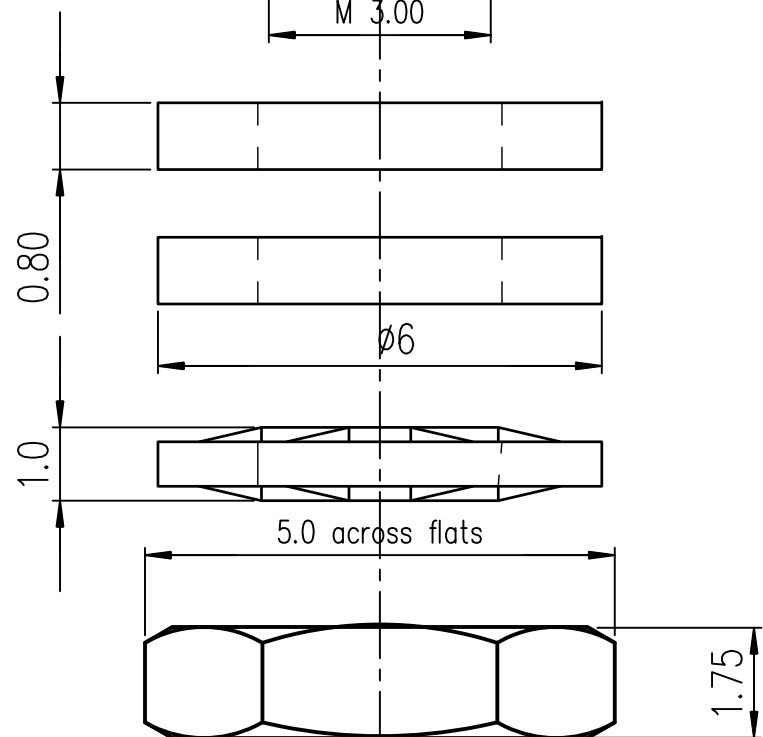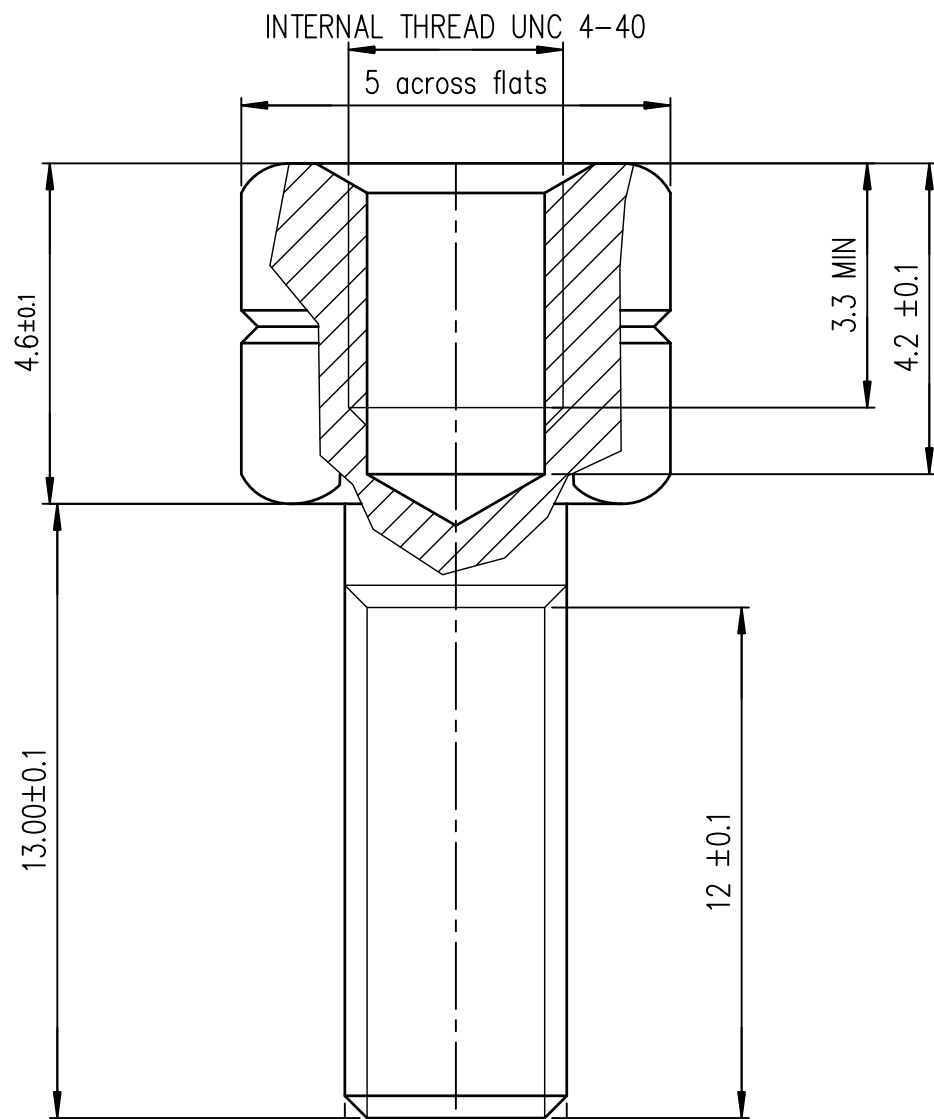

TECHNICAL CHARACTERISTICS :

- Female screw locks: brass, tin plated .
- Compensating washer: steel , tin plated .
- Nuts : steel , tin plated .
- Locking washer: steel , tin plated .

Packaging : per 100 pieces .

- a plastic bag=
- a bag of 100 screws
- a bag of 100 nuts
- a bag of 100 locking washers
- a bag of 200 compensating washers

Part number 863001061TLF

NOTE:RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper

European Views

rev	ecn no	dr	date
C	LS05-0026	MPE	2005/06/20
D	LS06-0208	LGO	2006/12/12
E	LS08-0048	MPE	2008/02/0048
F	LS09-0006	PCR	2009/01/08
G	I09-0240	AMR	2009/10/28
H	I11-0022	AMR	2011/01/25
-	-	-	-

www.fciconnect.com			surface ISO 1302 ✓	tolerance std ISO 406 ISO 1101	projection mm
TOLERANCES UNLESS OTHERWISE SPECIFIED					
Dr	MASSON	2000/08/01	ANGULAR	0.X	±0.1
Eng	P LEGARE	2005/02/16	LINEAR	0.XX	±0.1
Chr	ABHILASH M R	2009/10/27	0.XX' ±2'	0.XXX	±0.1
Appr	SUDHIR VARMA	2009/10/27	Product family		D-SUB
size					A3
Scale					10
ECN					I11-0022
Spec ref					-
title			FEMALE SCREW LOCKS		
D SUB ACCESSORIES			dwg no C01-8655-1541		
Rev.			H		
catalog no			CUSTOMER sheet 1 of 1		