

Features


- Ideal for basic needs whilst being commercially viable
- Flexible with good compression strength for medium/high loads
- Moderate strength: 2.5MPa tensile strength and 200% elongation
- Not suitable for: Oils, greases, fuels, solvents, prolonged UV exposure, or ozone
- Weathering: May degrade quickly outdoors due to UV and ozone

RS PRO Black Nitrile Rubber Sheet

10m x 1.4m x 1mm

+70°C to -20°C

RS Stock No.: 0205492

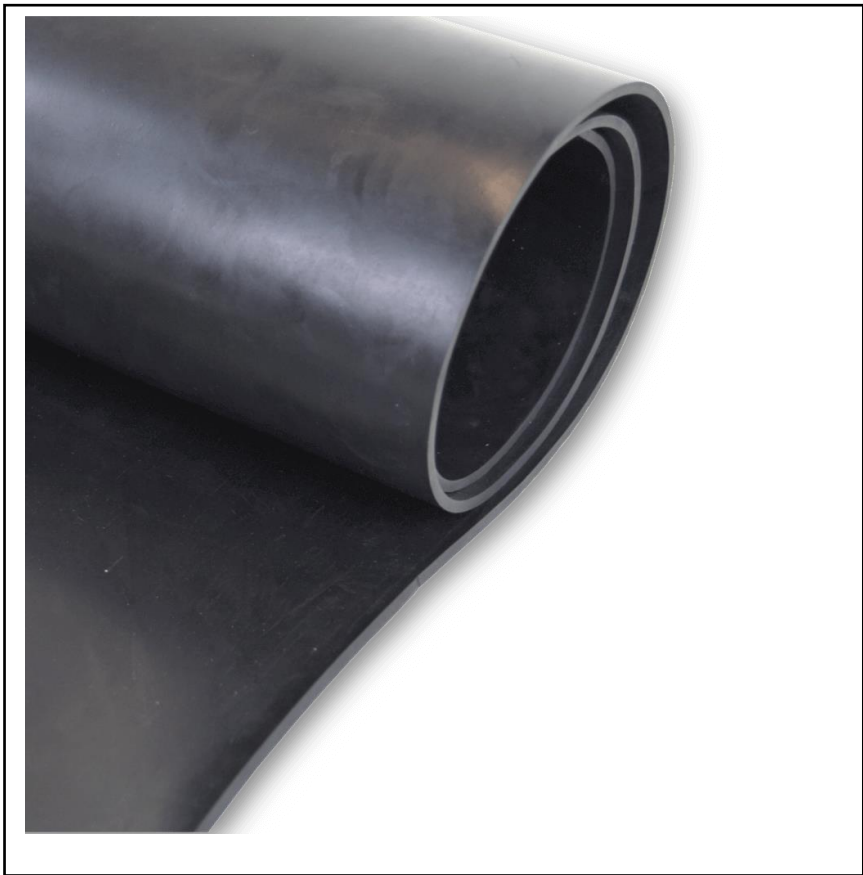

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

The RS PRO Nitrile Rubber (NBR) sheet is suitable for a wide range of applications and environments including waterproof seals and low pressure gaskets, barriers protecting surfaces from moisture and dust and bench covers providing anti-slip and cushioning to surfaces.

General Specifications

Colour	Black
Material	Nitrile Rubber (NBR)
Adhesive Backing	No

Mechanical Specifications

Length	10m
Width	1.4m
Thickness	1mm
Elongation	250%
Tensile Strength	3 MPa
Hardness	70 ShA

Operation Environment Specifications

Maximum Operating Temperature	70°C
Minimum Operating Temperature	-20°C

Similar Products

Stock No	Length	Thickness
0205492	10m	1mm
0205493	10m	1.5mm
0205494	10m	2mm
0205495	10m	3mm
0205496	10m	4mm
0205497	10m	5mm
0205499	10m	6mm
0205500	10m	8mm
0205501	5m	10mm
0205502	5m	12mm
0205503	5m	15mm
0205504	5m	20mm