



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts


TE Part # 184095-2 RECPT, CONTACT .070, PTPPHBZ	TE Part # 184373-1 CONTACT, RECEPTACLE, .070 TYPE	TE Part # 184095-1 RECPT, CONTACT .070, AUPHBZ	TE Part # 184030-1 RECPT, CONTACT 070, AUPHBZ



TE Part # 184141-1
WIRE SEAL,RUBBER,SENSOR,PURPLE,
LIM



TE Part # 184140-1
WIRE SEAL,RUBBER,SENSOR,
ORANGE

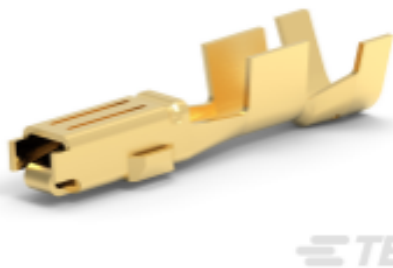

TE Part # 184289-1
RECPT, CONTACT 070, AUPHBZ



TE Part # 184294-1
1 POS PLUG ASSY KEY C



TE Part # 172748-1
E-J MK-2 070 CAVITY PLUG



TE Part # 184373-2
CONTACT, RECEPTACLE, .070 TYPE



TE Part # CAT-EC7491-T273
Econoseal Receptacles and Tabs



TE Part # 184042-1
1 POS. PLUG ASSY, KEY A



TE Part # 184139-1
WIRE SEAL,RUBBER,SENSOR,BLUE




TE Part # 184240-1
1 POS. PLUG ASSY, KEY B



TE Part # 184289-3
RECPT, CONTACT 070, PTPPHBZ



TE Part # 2289050-1
1 POS. PLUG ASSY, KEY A, HIGH
TEMP 150C

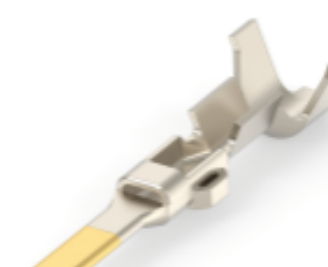

TE Part # 171631-2
070 TAB CONT GOLD



TE Part # 184030-3
RECPT, CONTACT 070, PTPPHBZ




TE Part # 172748-2
E-J MK-2 070 CAVITY PLUG

Customers Also Bought



TE Part #CAT-L489-CH8172
LEAVYSEAL Connector Housings

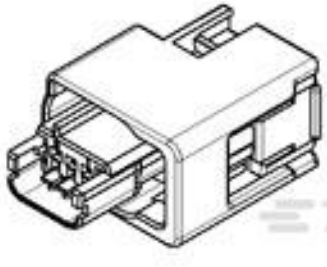


TE Part #1438454-1
0.64MM,3 POSN SEALED PLUG ASSY




TE Part #1-936119-1
4POS MQS REC




TE Part #CAT-M4595-T273
MCON Receptacle and Tab

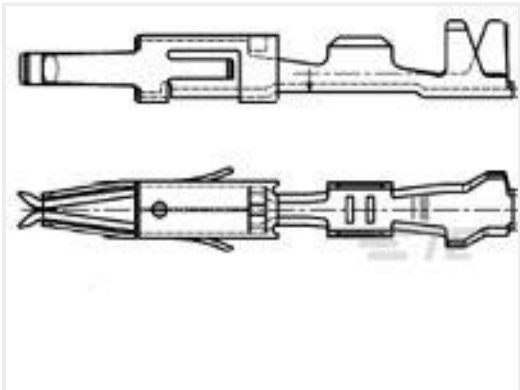

TE Part #968052-1
MT3 REC 1.6 Contact SRC Sn

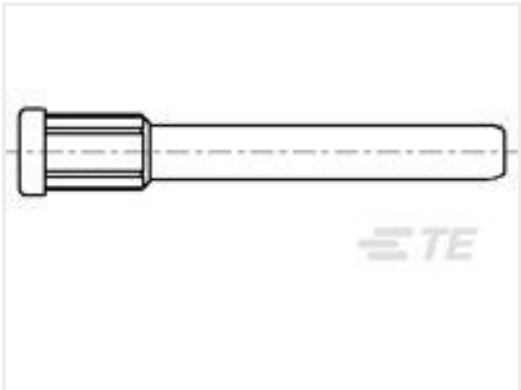

TE Part #1612108-4
025/040 CAVITY PLUG

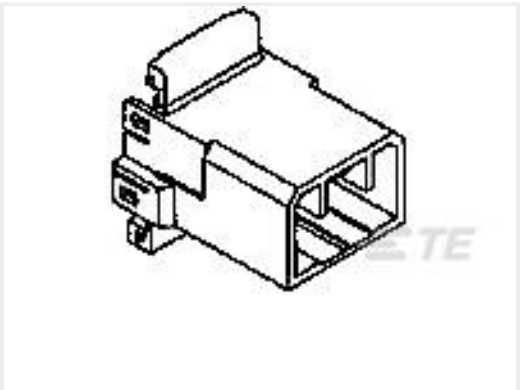

TE Part #282370-1
070 MULTILOCK CAP HSG 8 POS



TE Part #1326030-9
2.8MM RECEPTACLE, UNSEALED, DU

Documents

Product Drawings

1 POS. PLUG ASSY, KEY A

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_184042-2_E.2d_dxf.zip

English

Customer View Model

ENG_CVM_184042-2_E.3d_igs.zip

English

Customer View Model

ENG_CVM_184042-2_E.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Product Specifications

Application Specification

English