


Data Sheet

SY/CC 2 core 2.5mm 50M

Cross Section:

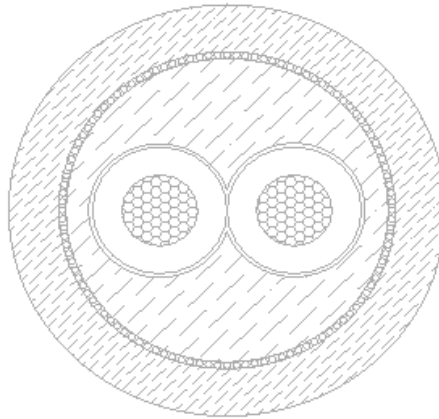

Description:

Rated Temperature (°C): -20 ~ 80
 Rated Voltage (V): 300

Construction:

Conductor: Bare Copper
 Conductor Dia. (mm): $0.25 \pm 0.008 \times 50$

Insulation: PVC

Insulation Dia. (mm): $3.4 \pm 0.1 \times 2C$

Filler: Chalk

Jacket 1: PVC

Outer Dia. (mm): 7.7 ± 0.2

Braid Shield: Galvanised Steel

Conductor Dia. (mm): 0.24

Conductor Qty: 24 x 4

Jacket: Trans PVC

Outer Dia. (mm): 10.78 ± 0.25

Colour:

The color of the insulation: Blue , Brown

The jacket color: Transparent

Marking(3times/m):

RS 522569 SY/CC 2 Core x 2.5mm²

Performance:

Electrical Characteristics:

Max. Conductor DC Resistance at 20°C (Ω/Km) :
 <8.2

Min. Insulation DC Resistance at 20°C (MΩ*KM) :
 >500

Current Rating : 20 A

