


# ST20 200W SOLDERING IRON

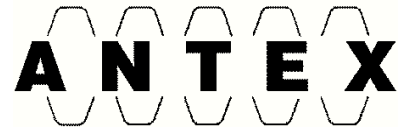

## DATA SHEET

**769-3126**




Iron featured without bit

### **SPECIFICATIONS ST20 (STRAIGHT) 200WATT SOLDERING IRON**

NOMINAL POWER (W)	200
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	430
FITTED BIT (D.F.)	¾" (19mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with European plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	850

DIMENSIONS: A: (bit) 50mm B: (handle & element) 250mm

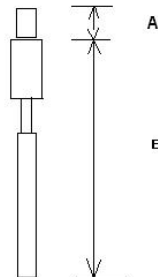

### TYPICAL APPLICATIONS:

General soldering on transformer casings, soldering on commutators up to 2" dia. & tin plate & metal box fabrications.