

Signal lamp with lamp socket, E 10, 16.2 mm, housing, screw terminal, 250 Volt, Nickel-plated screw terminal



fields of application

- Measurement-control-regulation
- Electrical engineering
- Mechanical and system engineering
- Signalling systems
- Model construction



description

Signal lamps for LEDs or filament/neon lamps with E 10 socket, mounting hole diameter 16.2 mm

technical data

➤ general

Bezel shape	round
illuminated	Yes
Lamp socket	E 10
Packaging unit	10 pcs.
net weight	7.8 g
Degree of protection, front side, according to DIN EN 60529	IP40
MOQ order	100 pcs.
RoHS compliant	Yes
REACH compliant	Yes

➤ mounting diameters

Mounting hole	16.2 mm
Mounting depth	41.5 mm
Collar dimension	20 mm

➤ mechanical data

Fixing	Threaded ring
Terminal on the rear	Nickel-plated screw terminal

➤ electrical data


Operating voltage of the luminous element, max.	250 V
--	-------

direct links

- [RAFI eCatalog](#)

drawings

Dimensioned drawing

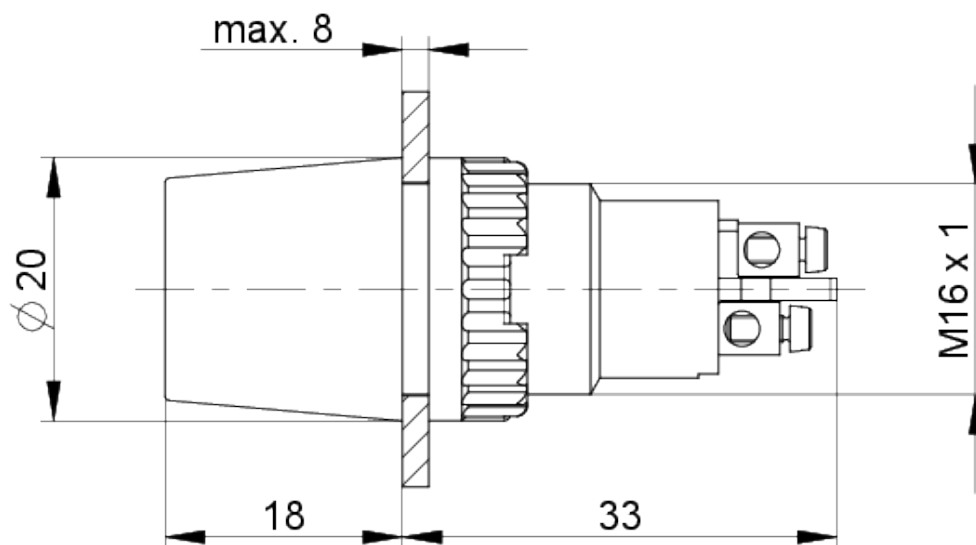

Mounting hole drawing

