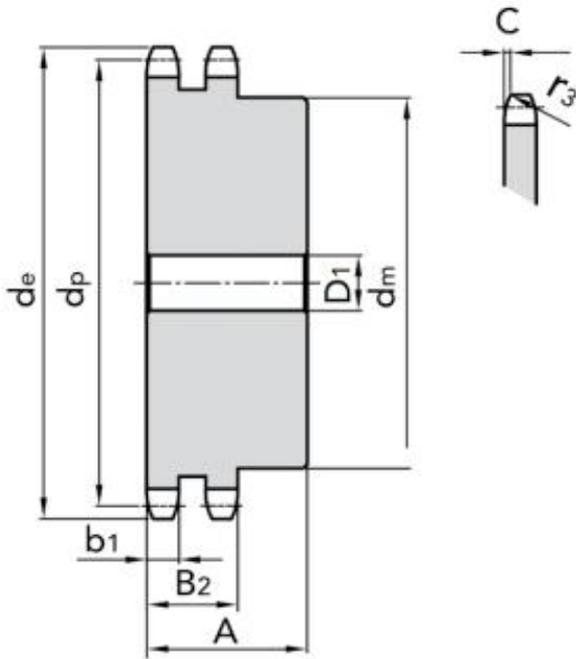


**10219015**

3/4in x 7/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**
**Technical Specifications**

Number of teeth (T)	15
de (DE) mm	99.16
dp (DP) mm	91.63
Part number (CODE)	10219015
dm (DM) mm	71
D1 (D1) mm	16
A (A) mm	50
Tooth radius r3 (R3) mm	19
Radius width C (C) mm	2
Sprockets tooth width b1 (B1) mm	10.8
Sprockets tooth width B2 (B2) mm	30.3
Weight (WEIGHT) kg	1.74
Material (MAT)	STEEL C 45