


Features

- "J" FeCu-Ni Type Thermocouples
- Max. operating temperature 200°C
- Sensor type DIN/IEC-584 "J" FeCu-Ni
- Cable type Silikon+Silikon
- Cable Length 2meter

RS PRO Standard Bayonet Type "J" Type Thermocouples

RS Stock No: 0350384

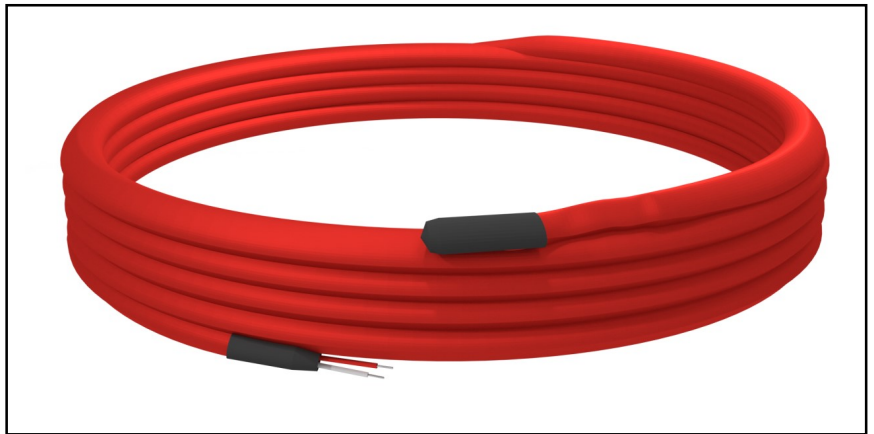

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Standard Bayonet "J" Type Thermocouples Temperature Sensor

Cable Length(K): 2m

Applications Fields

- Machinery Manufacturing
- Panel Manufacturing
- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications


General Specifications

Max. Operating Temperature	0 °C / +200 °C
Standard cable types	Silicone+Silicone
Sensor type	"J" Type Thermocouples (DIN/IEC-584)

Mechanical Specifications

Cable Length (K)	2m
------------------	----

Electrical Connection

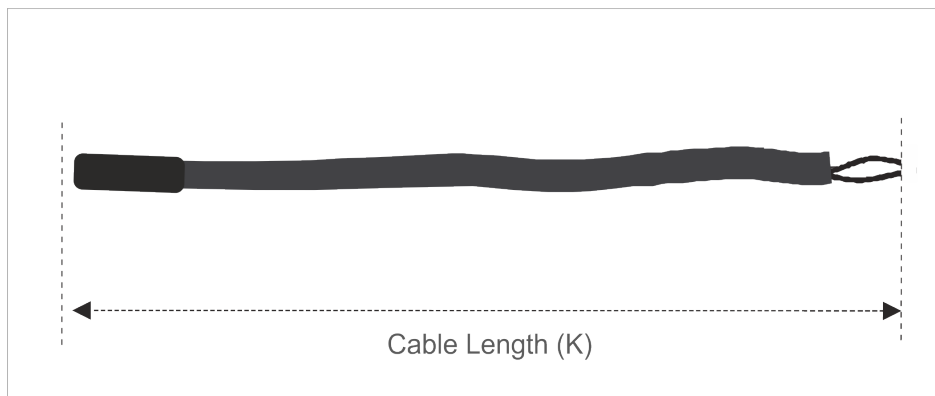

Thermoelement Connections

