

## Datasheet

# Insulated Crimp Spade Connector, 16 → 14 AWG, M6, Blue Vinyl

RS Stock number [534-604](#)



## Specifications:

1. **Maximum Electric Rating:** 75°C 600V

最高溫度: 75°C 耐壓 600V

2. **Maximum Electric Current:** (最大電流)

22-16AWG / 0.5-1.5mm<sup>2</sup>: 19A

16-14AWG / 1.5-2.5mm<sup>2</sup>: 27A

12-10AWG / 4-6mm<sup>2</sup>: 48A


3. **Terminal Body:** Copper (端子材質: 紅銅)

4. **Insulation:** Vinyl (護套材質: PVC)

5. **Plating:** Tin (表面處理: 鍍錫)

VM—Flared Vinyl without copper sleeve

PIPG—Pre-insulated funnel Vinyl insulator with easy entry copper sleeve

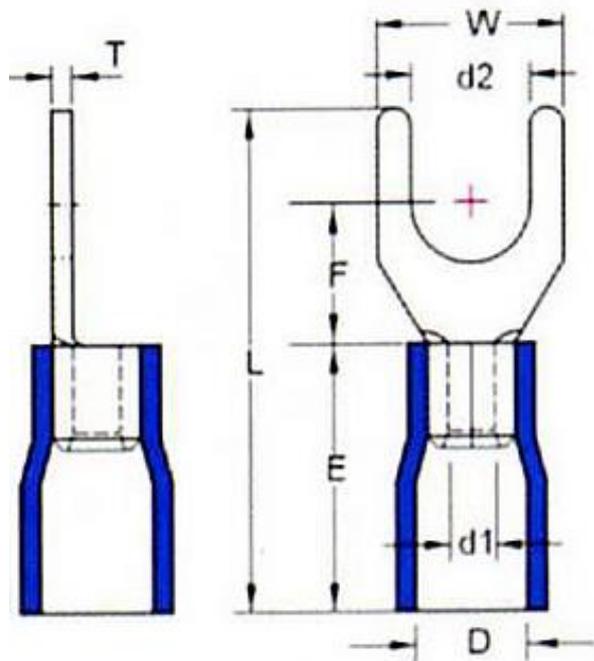

Insulation Colour	Wire Range Mm <sup>2</sup> /Awg	Stud Size	Dimension (mm)
Blue	1.5-2.5mm <sup>2</sup> /16-14AWG	#1/4/6.4	11.0/11.0/26.5/10.0/4.5/2.3/0.8