


926895-1 Soft Shell Connectors
Soft Shell - Contacts

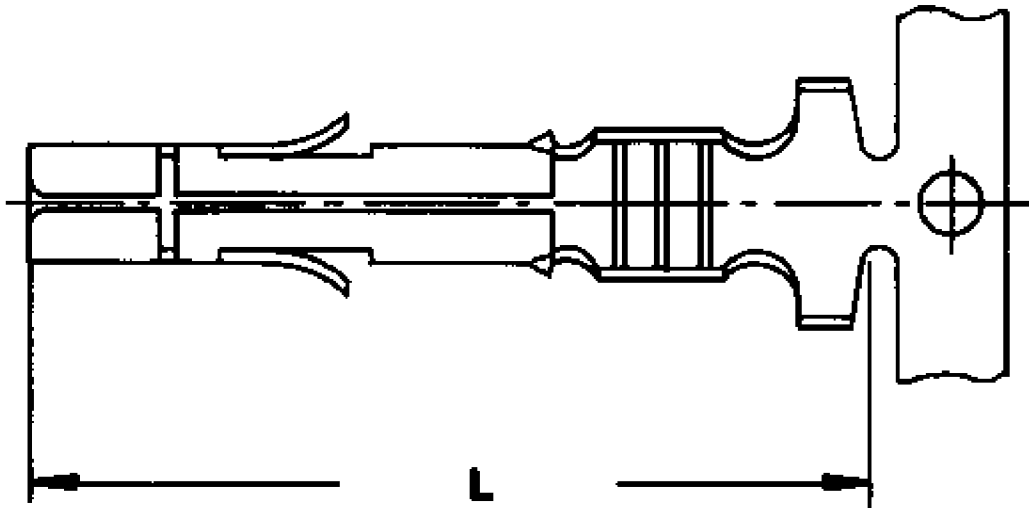

Line art represents typical product only.

<i>Searchable Features:</i>	
Connector Line	Universal MATE-N-LOK
Contact Diameter	.084 [2.13] in. [mm]
Contact Type	Socket
High Current	No
Mount	Wire Crimp
Wire Range	24-18 [0.20-0.80 ²] AWG [mm]
Insulation Diameter	.098 [2.50] Max. in. [mm]
Material	Brass
Finish	Pre Tin
Packaging Method	Loose Piece
<i>Other Properties:</i>	
Dim. L	.760 [19.30] in. [mm]