



Technical data

NA4908LL/3AS

Needle roller bearing, machined-ring, with inner ring

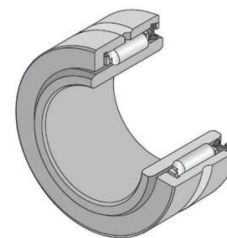

VISUAL (S)

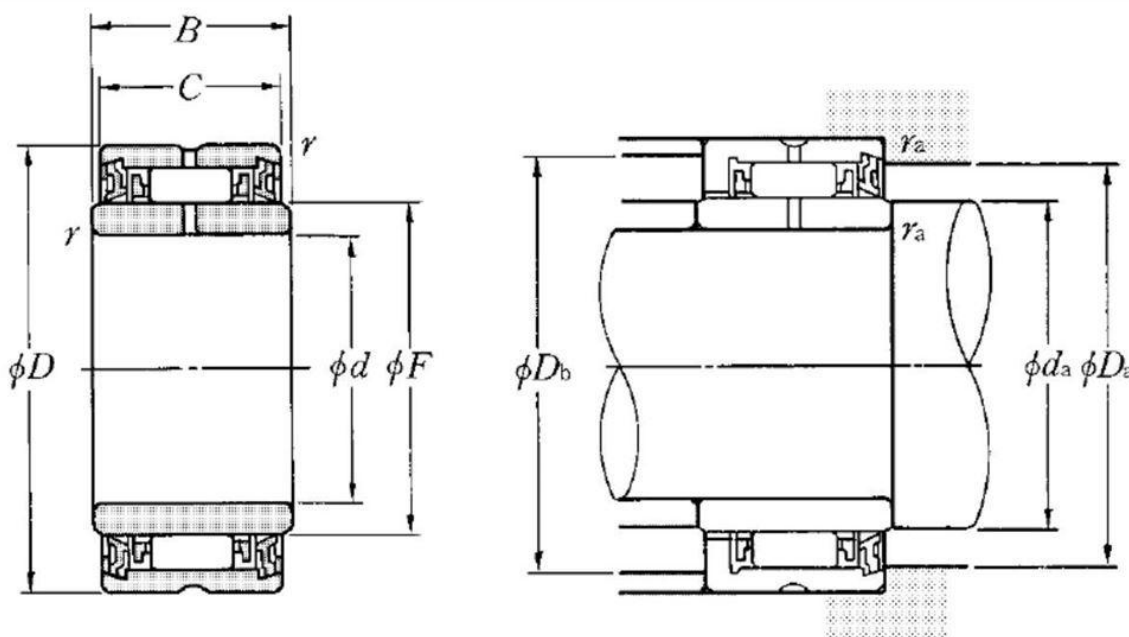

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	40 mm
D - External diameter	62 mm
B - Bearing/Inner ring width	23 mm
C - Width of bearing, drawn cup or outer ring	22 mm
F - Under roller diameter	48 mm
rs - Min fillet radius	0,6 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	3 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

NA4908LL/3AS

Needle roller bearing, machined-ring, with inner ring

PRODUCT DEFINITION

Lubrication hole on inner ring	Oui/Yes
Radial clearance class	CN
Precision class	P0
Mass	0,252 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	27,8 kN
C0r - Static load rating	53,5 kN
N lim - Grease lubrication limit speed	4200 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ABUTMENT

da min - Min shoulder diameter IR	44 mm
Da max - Max shoulder diameter OR	51 mm
Db max - Max OR shoulder diameter	58 mm
ras max - Max shaft & housing fillet radius	0,6 mm

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	NA4908LL/3AS
Image	NRBNA49_LL_1.jpg, NRBNA49_LL_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15