


Product data sheet

179 N W-8/244 EAN-No. 4000896**223046**

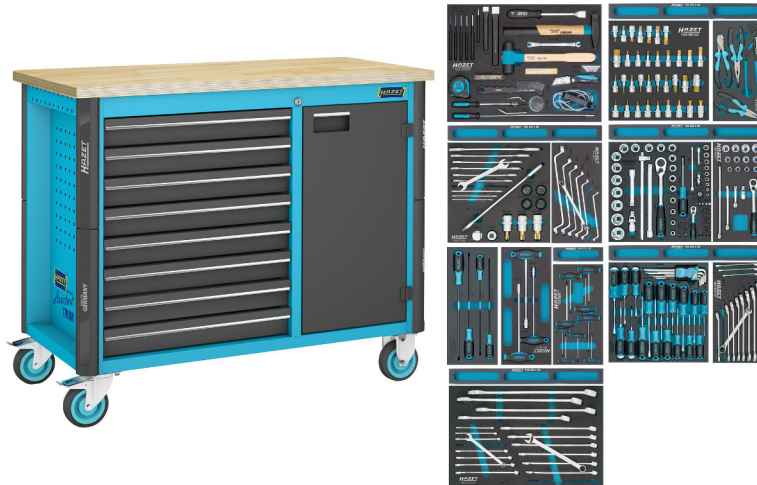

244-pieces · 8 Drawers total



- More storage space than preceding model
- 8 flat drawers
- Complete with 244-piece tool assortment in Safety-Insert-System soft foam insert
- 30 mm wood multiplex birch work surface, oiled, replaceable
- Including nine-fold adjustable intermediary tray and fixed mounted door
- Cable aperture on rear panel allows, for example battery-powered devices to be charged when the door is locked
- Complete welded construction of the entire body for tough daily workshop use
- Additional square perforation for tool holder, e.g. HAZET 112-230
- Optimised, yielding edge protection on all four corners with real impact protection thanks to internal damping concept
- Flexible vice assembly (front, right, left) e.g. HAZET 2175N as per drilling templates
- **Chassis:**
 - Large wheels with high loading capacity (Ø 125 mm) with precision ball-bearing and dual ball race in the swivel bearing, easy manoeuvrability even under high dynamic load
 - 2 swivel castors with dual brake:
 - Braked castors prevent rolling away
 - Braked swivel bearings prevent the swivel castors from turning, e.g. on inclined surfaces
 - Protective ring prevents dirt and threads from getting in
 - Elastic castors enable smooth movement
- **Locking concept:**
 - Mutual drawer locking for minimum tilting risk
 - Lock located in the centre (central locking and cylinder lock) closes the door and drawers at the same time
 - Only one key for locking the door and drawers at the same time (Included in delivery: 2 keys)
 - 180° rotation, prevents the key from breaking off
 - 100 % sliding-out with ball-bearing telescopic rails – self-closing
 - Lockable storage compartment with 2 storage surfaces
- 2 storage spaces in the storage compartment, top: 15 kg / bottom: 35 kg
- Total loading capacity (dynamic): 750 kg
- Loading capacity (static): 1000 kg
- Worktop: Wood multiplex birch, replaceable
- Colour: HAZET blue
- Tool trolley Made in Germany
- Dimensions: 1150 mm x 600 mm x 964 mm
- Net weight: 120 kg
- Drawers, flat: 8 x 81 x 522 x 398 mm

- (Drawer) size for plastic drawer insert: 3/3+
- Worktop: Wood multiplex birch, replaceable
- Number of fixed castors: 2 (Ø 125 mm)
- Number of swivel castors: 2 (Ø 125 mm)
- Number of tools: 244

Order Number

179 N W-8/244

179NW-8

163-181/17 • • 3⁄₁₆

880 • • 3⁄₁₆
10 • 11 • 12 • 13 • 14 • 15 •
16 • 17 • 18 • 19 • 21 • 22

8816HP • 3⁄₁₆

8820 • 3⁄₁₆ • 3⁄₁₆

8821 • 3⁄₁₆ • 3⁄₁₆
8821-3 • 8821-6 • 8821-10

163-182/9 •

828-T •
T6 • T7 • T8 • T9 • T10 •
T15 • T20 • T25 • T30

163-210/19 •

600N •
8 • 9 • 10 • 11 • 12 • 13 •
14 • 15 • 16 • 17 • 18 • 19 •
21 • 22 • 24 • 27 • 30 • 32 •
34

163-211/20
, , 3⁄₁₆

450N •
8 x 9 • 10 x 11 • 12 x 13 •
14 x 15 • 16 x 18 • 17 x 19 •
20 x 22 • 21 x 22 • 24 x 27 •
30 x 32 • 34 x 36

1010 • • 3⁄₁₆
14 • 17 • 19 • 22

1012 • • 3⁄₁₆
T60 • T80 • T100

1058-1 • 1" • 3⁄₁₆

1058-2 • 1⁄₂ • 3⁄₁₆

163-224/57N
, , , , , • 1⁄₂, 3⁄₁₆,
 1⁄₁₆

811BML • 3⁄₁₆

850 • • 3⁄₁₆
5.5 • 6 • 7 • 8 • 9 • 10 • 11 •
12 • 13

863HP • 3⁄₁₆

867-2 • 3⁄₁₆ • 3⁄₁₆

868 • 3⁄₁₆ • 3⁄₁₆

869 • 3⁄₁₆ • 3⁄₁₆

900 • • 1⁄₂
10 • 11 • 12 • 13 • 14 • 15 •
16 • 17 • 18 • 19 • 20 • 21 •
22 • 23 • 24 • 26 • 27 • 28 •
30 • 32

915 • 1⁄₂

916HP • 1⁄₂

917-5 • 1⁄₂ • 1⁄₂

918-10 • 1⁄₂ • 1⁄₂

920 • 1⁄₂ • 1⁄₂

2204N • • 3⁄₁₆
3 • 4 • 5 • 6 • 8

2208N • • 3⁄₁₆
0.6 x 4.5 • 1 x 6 • 1.2 x 6.5

2215N • • 3⁄₁₆
PH1 • PH3

2216N • • 3⁄₁₆
PZ1 • PZ2

2223N • • 3⁄₁₆
T15 • T20 • T25 • T30

2250-1 • 3⁄₁₆ • 3⁄₁₆

2304N • 3⁄₁₆ • 3⁄₁₆

163-257/4

760-2

1802M-22

1841MB-33

1850M-22

163-296/7 •

630 •
6 x 7 • 8 x 9 • 10 x 11 •
12 x 13 • 14 x 15 • 17 x 19 •
21 x 22

163-297/26N
, ,

811 •
0.5 x 3 • 0.8 x 4 • 1 x 5.5 •
1.2 x 6.5

811PH •
PH1 • PH2

Product data sheet

179 N W-8/244

EAN-No. 4000896223046



811T • •
T10 • T15 • T20 • T25 •
T27 • T30



811S • •
0.8 x 4.5 • 1 x 5.5 • 1.2 x 7



811SPH • •
PH1 • PH2



2105LG/9H • •



163-372/25 •

612N • •
10 x 11



666-5

730
730-3 • 730-6

746-1

748B
748B-3 • 748B-4 • 748B-5 •
748B-6 • 748B-8

824 • •
0.5 x 23



1952-40



1976-2

2140-40

2147MS



2152N/3



 
2154N-5



2157-1



4968-2



163-380/4N •



811LGT • •
T15 • T20 • T25 • T30



163-382/3 •

428 •

 
8 • 10 • 13



163-385/12 •

606 •

8 • 9 • 10 • 11 • 12 • 13 •
14 • 15 • 16 • 17 • 18 • 19



163-407/35

• • • • •

986 • • •

4 • 5 • 6 • 7 • 8 • 9 • 10 •
12 • 17 • 19 • 22

990 • • •

M5 • M6 • M8 • M10 • M12 •
M14 • M16 • M18

991 • • •

M6 • M7 • M8 • M9 • M10 •
M12 • M14

992 • • •

T20 • T25 • T27 • T30 •

T40 • T45 • T50 • T55 • T60



163-522X50



163-172X50