


## FEATURES

- **Heat Stabilised:** Ensures performance in high-temperature environments up to 105 °C
- **High Tensile Strength:** Supports up to 22 kg, providing robust cable management
- **UL 94 V-2 Fire Behaviour:** Offers flame retardant properties for enhanced safety
- **Length of 368 mm:** Suitable for bundling larger cable groups
- **Maximum Bundle Diameter of 105 mm:** Accommodates a wide range of cable sizes
- **Nylon Material:** Provides durability and resistance to wear
- **RoHS Compliant:** Meets environmental and safety standards

## RS PRO Heat Stabilised Cable Tie, 368 mm Nylon

RS Stock No: 656-023

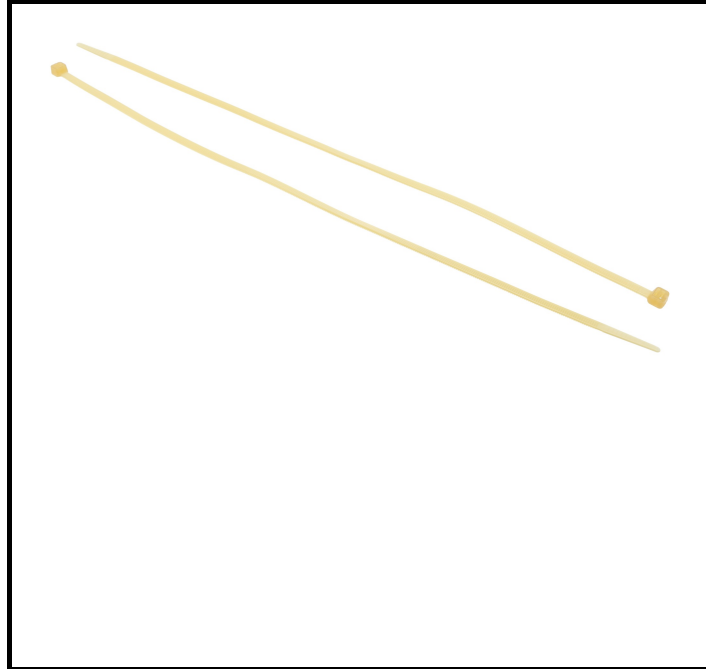

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

The RS PRO Heat Stabilised Cable Tie is designed for secure and reliable bundling of cables and wires. Made from durable nylon, it offers excellent performance in environments with elevated temperatures, making it ideal for industrial applications.

### General Specifications

Colour	Light Green
Product Type	Cable Tie
Sub Type	Heat Stabilised
Tensile Strength	22 kg

### Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

### Mechanical Specifications

Length	368 mm
Material	Nylon
Maximum Bundle Diameter	105 mm
Width	4.8 mm

### Operation Environment Specifications

Maximum Operating Temperature	105 °C
-------------------------------	--------

### Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

