

Actuator

45-
2828.1E90.001

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-2828.1E90.001>

Your product:



45-2828.1E90.001 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front form:	Round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lever colour:	White
Lever material:	plastic
Lever shape:	round

ELECTRICAL CHARACTERISTICS

Switching rating:

MECHANICAL CHARACTERISTIC

Switching action:	Rest - Maintained
Switching positions:	2 positions
Switching angle:	90° right / -45° ... +45°

Mechanical lifetime: 1 Mil. cycles of operation

Operating frequency: 1 800/h

Weight: 0.026 kg

AMBIENT CONDITION

IP front protection: IP66, IP67, IP69K

Operating temperature: – 25 °C ... + 70 °C

Storage temperature: – 40 °C ... + 80 °C

Shock resistance: According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance: According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

Climate resistance: During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER


Short Description: Actuator, Ø 22.3 mm, Ø 29,5 mm, optional illuminative, White, round, Round, Black, Plastic, Rest - Maintained, IP66, IP67, IP69K

Housing material: Plastic


Switching positions:

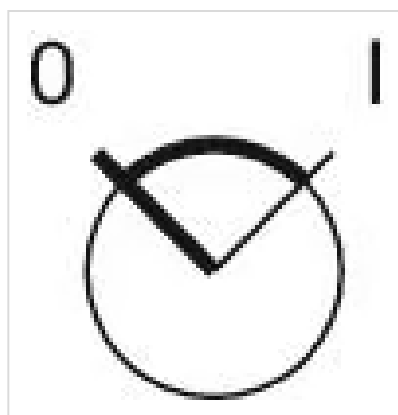

Wiring diagrams:

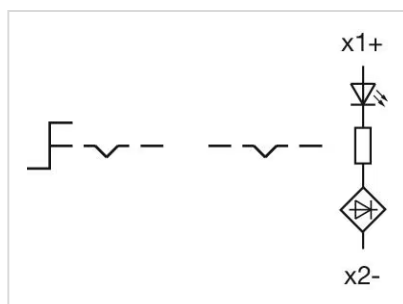

Mounting cut-outs:

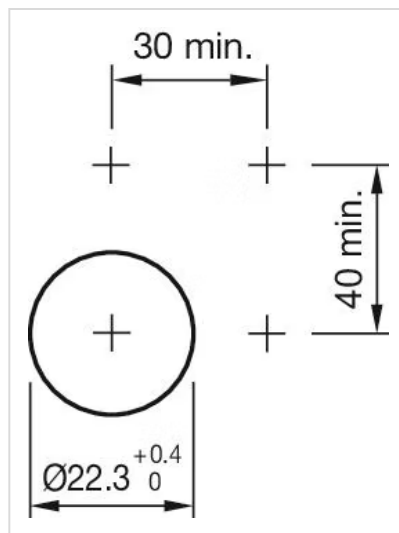

Dimension drawings:

