


# multiple distributor NPQM-LFK-G18-Q8-P10

Part number: 558839

FESTO

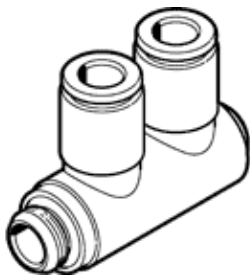

## Data sheet

Feature	Value
Size	Standard
Nominal size	6 mm
Type of seal on screw-in stud	Sealing ring
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Nominal tightening torque	6 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	50 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	For tubing outside diameter 8 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material hollow bolt	Nickel-plated brass
Material of tubing seal	NBR