



**Part No.** 199112028

**Series** Compressed Air Hose Reels – Closed

3D

PDF

Inquiry List

<b>Category title</b>
Small reel
<b>Reel type</b>
Closed reel
<b>Hose length on reel</b>
10 m
<b>Material hose</b>
PUR
<b>Reel material</b>
Plastic
<b>Weight (kg)</b>
4.9 kg
<b>ID x OD (mm)</b>
8.0 x 12.0 mm

---

**Min temperature (C)**

-20 °C

---

**Max temperature (C)**

60 °C

---

**Connection Inlet**

R 1/4" Male

---

**Connection Outlet**

R 1/4" Male

---

**Max working pressure (bar)**

16 bar

---

**Hose variants**

Hi-vis

---

**Hose colour**

Hi-vis green

---

**Media reels**



Compressed air

---

## Compressed Air Hose Reels – Closed

The CEJN Safety Reel is a durable reel that provides excellent performance thanks to its full-flow patented design that, unlike most reels, does not restrict flow. This provides maximum power to the customer's tools, saving them both energy and time. This hose reel is ideal for a safe workplace. The slow retraction function, hose guiding, PUR hose, soft stop-ball to prevent tripping and anti-kink safety features are just a few examples of what makes these safety reels the best on the market. The reel can swivel 180 degrees allowing the operator to move around freely, and the slow retraction makes it safe and easy for anyone to handle. If a hose needs to be changed, this can be done easily thanks to its smart design.



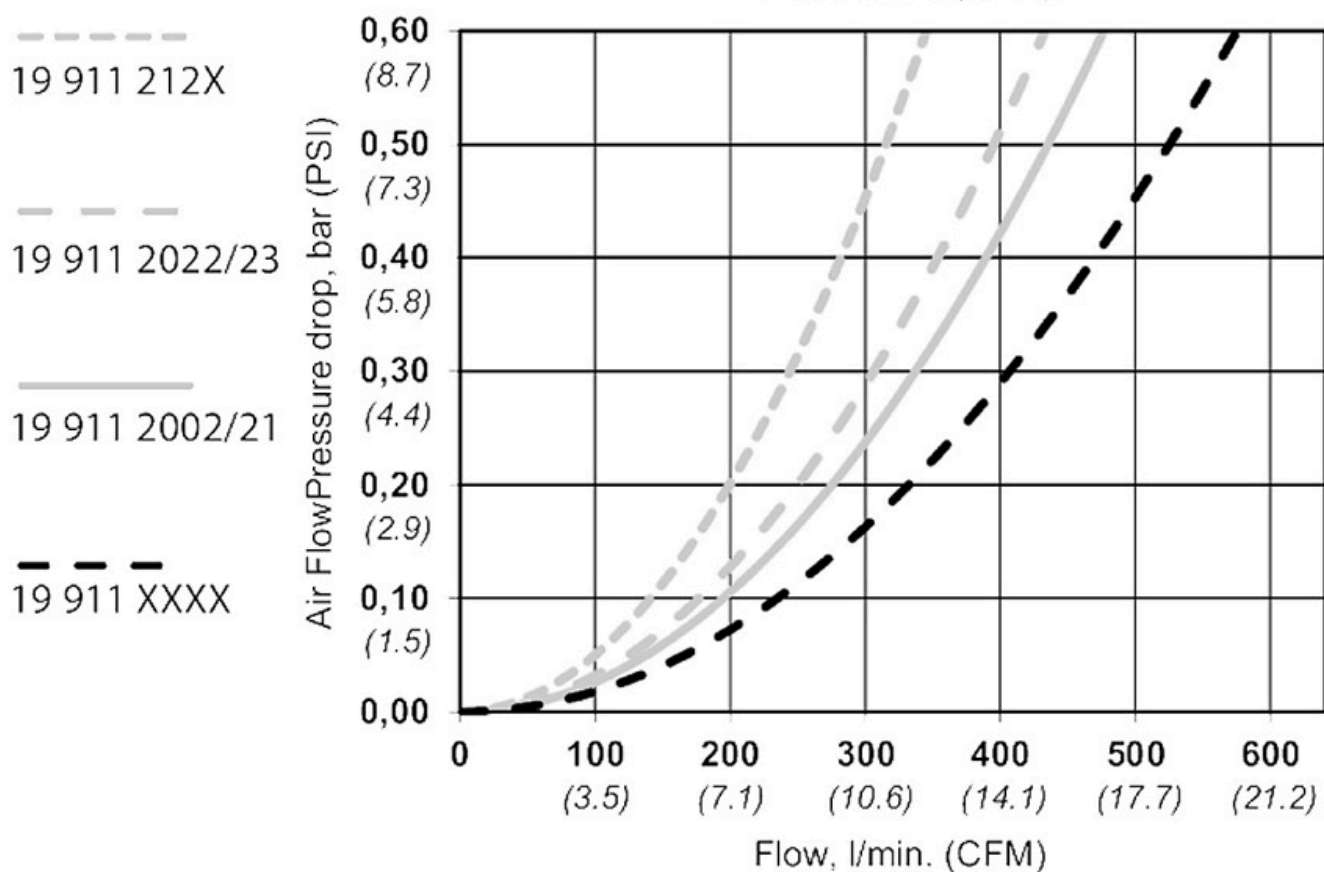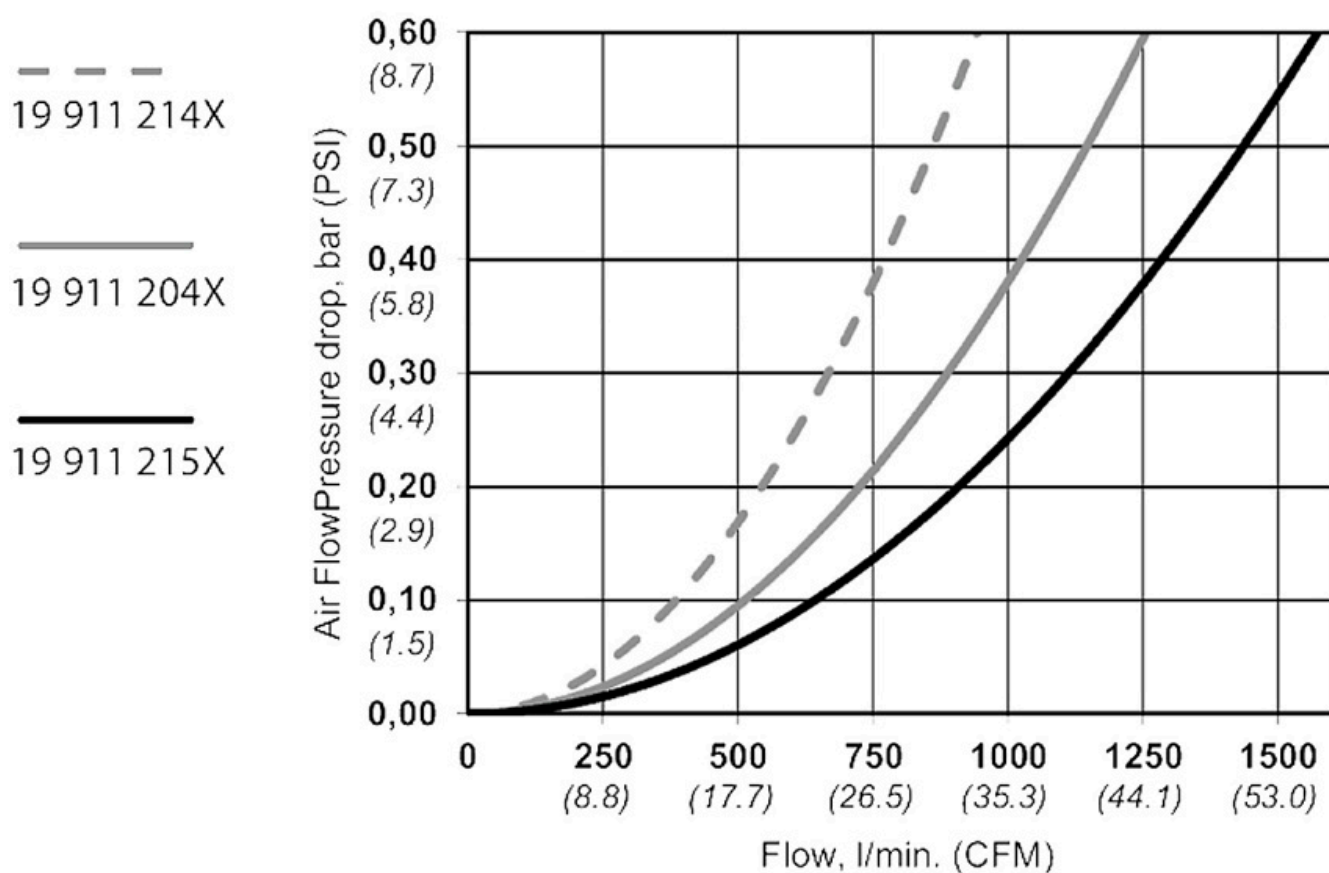

#### Air Flow

x: Chart flow l/min (CFM)

y: Chart pressure drop bar (PSI)

---

Check with an authorized CEJN distributor for availability and prices. All measurements are in mm. Other connections and sealing material on request. Some part numbers may be subject to minimum order quantities. CEJN reserves the right to make changes without further notification. Thread connections are listed according to ISO standards, unless stated otherwise.