


PXA911/04/P/08 Datasheet

Product Name // Flex Cable Connector Large Cable
PXA911 Series 4 Contact Plug 16mm-18mm Cable (White Gland)

 [View Product Page](#)

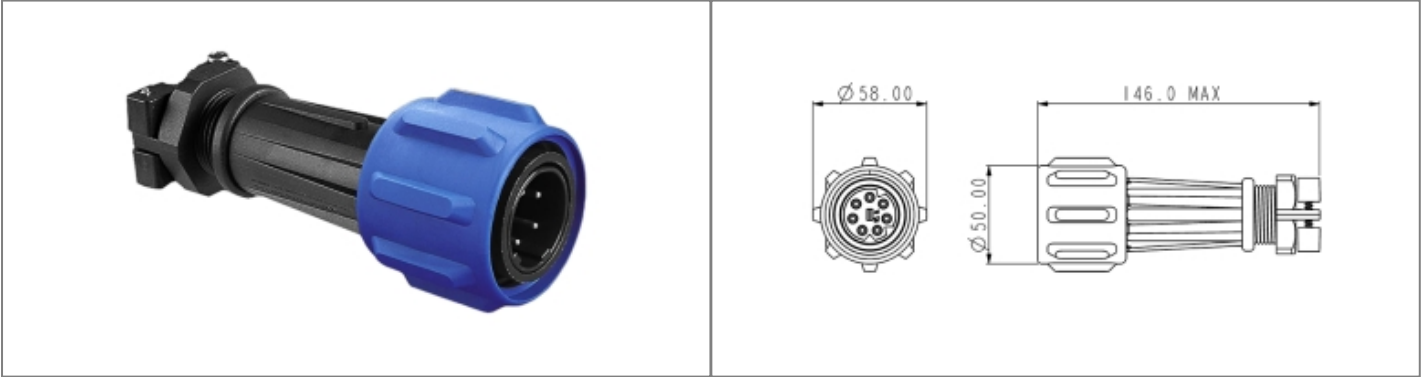

// Product Description:

- Flex Cable Connectors
 - Water and dustproof to IP68 when mated with compatible connector
 - Positive fast-acting locking ring - can be turned with a gloved hand
 - Plug or Socket
 - 2, 3, 4, 5, 7, 10 Contact with leading Earth on 3, 4, 5, 7 Contact versions, trailing Neutral on 5 Contact version
 - Screw Terminals
- Choice of cable acceptance 7mm-22mm diameter depending on part code (see data for details):
 - PX09 part codes 7mm-15mm diameter
 - PXA9 part codes (large cable version with strain relief clamp) 14mm-22mm diameter
 - Packs of Cable Glands for differing cable diameters available separately (PX0980, PXA980)
 - PX0960/PX0990 Sealing Caps available separately to maintain IP rating of unmated connectors
 - Mate with PX09 or PXA9 Series Flex and Panel Mount Connectors, as appropriate

// General Information:

Product Display Title:	Flex Cable Connectors
Product Family:	Circular Power Connectors
Product Series:	900 Series Buccaneer
Approvals:	UL
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	32A
Diameter Over Coupling Ring Mm:	58mm
Flamability Rating:	UL94V-0
Function:	Flex Cable Connector
Ip Rating:	IP68
Max Cable Entry Size:	18mm
Min Cable Entry Size:	16mm
Max Contact Accomodation Awg:	13AWG
Min Contact Accomodation Awg:	10AWG
Max Contact Accomodation Mm2:	4mm2
Min Contact Accomodation Mm2:	2.6mm2
Max Operating Temperature:	+85°C
Min Operating Temperature:	-40°C
Number Of Contacts:	4 Contacts
Voltage Max:	600V

// Product PDF Links

-  [900 Series power connectors...](#)
-  [900 Series power connectors wiring...](#)

// Product 3D CAD Model Links

-  [PXA911/04/P/083D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)