


## S1125 Adhesive

A flexible two part epoxy adhesive

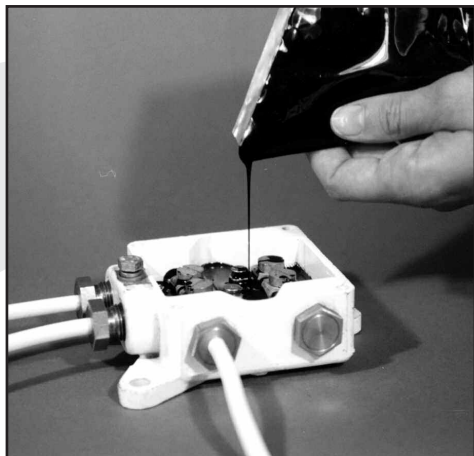

### Description

S1125 is a flexible two part epoxy adhesive available in a range of kit formats. The duo-syringe, applicator and mixing nozzle provide an easy to use system, that requires no mixing, can be used again, if re-sealed after use, ensuring minimal waste.

### Features & Benefits

- Easy to use, no mixing required and less waste
- Can be applied directly to the application
- Once mixed the adhesive has a 1 to 2hr pot life at room temperature
- Suitable for use with a wide range of materials and applications

### Operating Temperature

- -55°C to +150°C

5

Ordering Description	Product Description
<b>Kit Options</b>	
S1125-Kit-1	5 x 10g sachet with 5 mixing cups, sticks, adhesive strips & installation leaflet
S1125-Kit-2	2 x 10g sachet
S1125-Kit-3	1 x 100g sachet
S1125-Kit-4	5 x 10g sachet
S1125-Kit-5	1 x 10g sachet
S1125-Kit-8	1 duo-syringe with 5 mixing cups, sticks, abrasive strips & installation leaflet
<b>Application Equipment</b>	
Handgun-050 (1:1)	Duo-syringe application gun
RT-Nozzle-5mm	Duo-syringe static mixing nozzle

**Note:** For further information on the S1125 adhesive or for technical, installation or safety datasheets, please contact us.