


Blue Elastic Rubber Trolley Wheel 125mm, stainless steel roller, 250kg

Elastic Rubber-tyred wheel

PRODUCT

Article number

571-511-125R20X

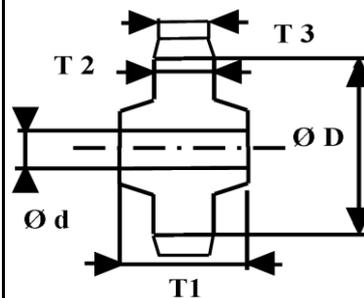

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, blue bonded elastic rubber tyre, non marking.
 Hub : symmetrical, stainless steel roller bearing.

TECHNICAL DATA

Specifications

Wheel Diameter - ØD ± 1%	125 mm
Hub Type	Stainless steel Roller Bearing
Hub Length T1	60 mm ±1
Width of Tread T2	50 mm ±1
Width of Tread-on floor T3	48 mm ±1
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	400 Kg
Temperature	-20 / +60 °C
Weight	0,55 Kg

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduce schok and vibration.
 Quiet in use and high wear resistance.
 Suitable for industrial floors and also all interior floors (catering, kitchen, humid ou corrosive environment thanks to the stainless steel roller).