

Cable sleeve - CES-SRG-BK-1ASI-L - 1410042

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Small, slotted cable sleeves suitable for one AS-i cable, material: NBR, version: left



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 776196
Weight per Piece (excluding packing)	8.62 g
Custom tariff number	40169300
Country of origin	Taiwan

Technical data

Dimensions

Conductor sealing range	AS-i cable
Length	29.5 mm
Width	19.5 mm
Height	17 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (static)
---------------------------------	----------------------------

General

Material	NBR
Color	black

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002

Cable sleeve - CES-SRG-BK-1ASI-L - 1410042

Classifications

eCl@ss

eCl@ss 5.0	27081002
eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002

ETIM


ETIM 3.0	EC000879
ETIM 4.0	EC002498
ETIM 5.0	EC000451

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Drawings

Dimensioned drawing

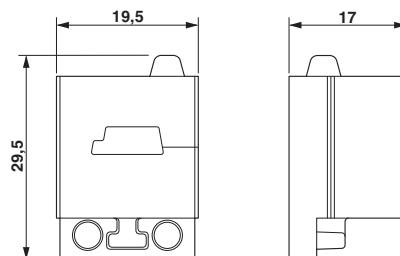

Dimensional drawing