


## Protective covers - HC-B 16-SD-FLU/FS-AL - 1644588


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

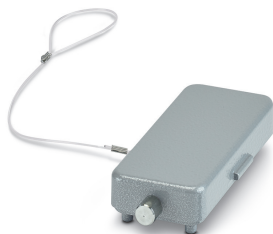

Protective cover B16, for single locking latch, protective cover material: Al, height: 16 mm, seal: no, diameter of retaining cord eyelet: 30 mm, with lanyard



### Key Commercial Data

Packing unit	10 pc
GTIN	 4 017918 904906
GTIN	4017918904906

### Technical data

#### Dimensions

Length	94 mm
Width	43 mm
Height	16 mm
Diameter of retaining cord eyelet	30 mm

#### Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Size	B16
Type	for supporting base element with single locking latch
Material	die-cast aluminum
Color	gray
Seal present	no
Connection	The guide pins of the protective cover must be removed when using coding sockets, pins, and bolts.

### Environmental Product Compliance

# Protective covers - HC-B 16-SD-FLU/FS-AL - 1644588


## Technical data

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

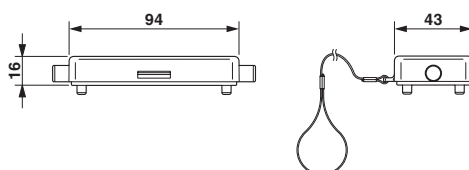

Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 10.0.1	27440208
eCl@ss 11.0	27440208
eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27149100
eCl@ss 5.1	27149100
eCl@ss 6.0	27261200
eCl@ss 7.0	27440208
eCl@ss 9.0	27440208

### ETIM

ETIM 2.0	EC000241
ETIM 3.0	EC002040
ETIM 4.0	EC002314
ETIM 6.0	EC002314
ETIM 7.0	EC002314

### UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121421
UNSPSC 18.0	39121421
UNSPSC 19.0	39121421

## Protective covers - HC-B 16-SD-FLU/FS-AL - 1644588

### Classifications

#### UNSPSC

UNSPSC 20.0	39121421
UNSPSC 21.0	39121421

### Approvals

#### Approvals

---

#### Approvals

EAC

---

#### Ex Approvals

---

### Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

---

Phoenix Contact 2022 © - all rights reserved  
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg  
Germany  
Tel. +49 5235 300  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>