


## Technical data sheet

### Article number:

**111-12440**

**T120L**

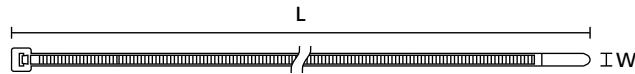

<b>Product Group</b>	Cable Ties for temperatures up to + 105°C (heat stabilised)
<b>Product Family</b>	T-Series in PA66HS black
<b>Material</b>	Polyamide 6.6, heat stabilised (PA66HS)
<b>Colour</b>	Black (BK)
<b>Application Tool</b>	ProCut 9 no battery, EVOcut, MK9P, MK9P w/ Upper air, MK10-SB, MK21, EVO9, EVO9SP, EVO9HT, EVO9i, EVO9iSP, EVO9iHT
<b>Bundle Ø max.</b>	225.0 mm
<b>Bundle Ø min.</b>	5.0 mm
<b>Flammability</b>	UL 94 V2
<b>Halogen-free</b>	Yes
<b>Height (H)</b>	7.8 mm
<b>Length (L)</b>	760.0 mm
<b>Min.Tensile Strength</b>	535 N
<b>Operating Temperature</b>	-40 °C to +105 °C
<b>Package Content</b>	50 pcs.
<b>Package Content packed in</b>	pcs.
<b>Releasable Closure (Yes/No)</b>	No
<b>Specifications</b>	IEC 60092 series
<b>Thickness (T)</b>	1.8 mm
<b>Toothing (Serration)</b>	Inside Serrated
<b>UV-Stabilised</b>	No
<b>Variant</b>	Inside Serrated
<b>Weight/Unit</b>	0.011611 kg
<b>Width (W)</b>	7.6 mm

**HF** ✓ **RoHS** ✓

