


---

Item no.: 870-831  
Product description: 4-conductor through terminal block

---

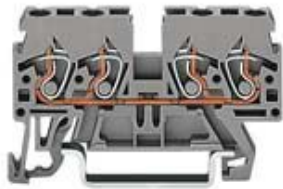

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	16 (RAIL MOUNTED TERMINAL BLOCK WITH CCC)
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Cross section [AWG]	28 - 14 AWG
Wiring method	s + f-st
Connection method	CAGE CLAMP®COMPACT CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 4 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Wiring method	f
Connection method	CAGE CLAMP®COMPACT CONNECTION
Measured voltage EN	500 V
Measured shock voltage	6 kV
Pollution degree	3
Current intensity EN	24 A
Weight	7.586 g
Color	grey
Wiring type	Front-entry
No. of connection Points	4
No. of potentials	1
Height	27.5 mm

Height  
Width  
Width

1.08 in  
5 mm  
0.197 in



Depth	55 mm
Depth	2.17 in
Strip length from	6 mm
Strip length to	7 mm
Strip length	0.26 in
Mounting	TS 35



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
870-831	ABS	05-HG476175/3-PDA	500		2,5
870-831	CCA	NL6826	500		2,5
870-831	cURus	E45172	300	20	28-12
870-831	DNV	E-9214	500		2,5
870-831	GL	17295-00HH	500		2,5
870-831	KEMA	2143311.01	500		2,5
870-831	LR	91/20112(E6)	500		2,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected