

## DPF series - Industrial type - anti-static polyurethane hose - ATEX



### Technical characteristics

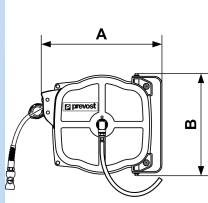
**Technology:** Pipe locked with ratchet stop

**Max operating pressure:** 12 bar

**Construction:** Epoxy-coated steel case

**Connection:** 1 m of inlet supply hose

180° swiveling bracket  
 Inlet : G 3/8F + 1 m hose  
 Pressure : 12 bar  
 Temperature : -15°C to +65°C

	A (mm)	B (mm)	ID/OD (mm)	Length (m)	Coupler	Flow rate (l/min)	Swivel inlet BSPP female thread	Weight (kg)	Parts Numbers
	377	317	10 x 14	12	ESI 07	800	G 3/8	7	<b>DPFEX 1012ES</b>
	377	317	10 x 14	12	ISI 06	800	G 3/8	7	<b>DPFEX 1012IS</b>
	377	317	10 x 14	12	CSI 06	800	G 3/8	7	<b>DPFEX 1012CS</b>