


QON2L40



QON120L125I

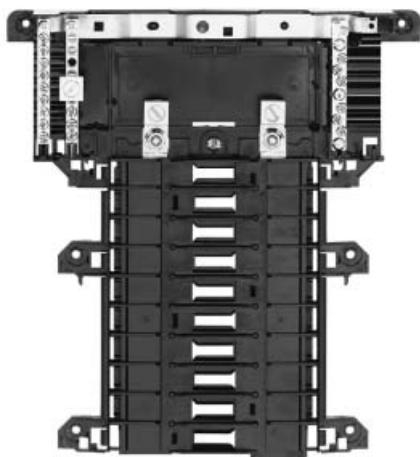

SN12125

**OEM Mounting Bases—UL and CSA Listed**

Voltage System	Main Lug Rating	1-pole Spaces	Max. No. 1-pole	Mounting Bases		Main Wire Size AWG/kcmil
				Catalog No.	Price	Cu/Al
<b>QO Plug-On Mounting Bases—For unit mounting QO, QO-GFI and QO-EPD circuit breakers</b>						
1 Phase 2 Wire 240 Vac Max. 10,000 AIC (Without Neutral Assembly)	70 A	2	2	QON2L70	\$ 18.20	#14-4 Cu, #12-3 Al
	125 A	4	4	SK9948BW	50.00	#12-1/0
	125 A	4	4	SK9842	52.00	#12-1/0
	125 A	6	6	SK9795	56.00	#12-1/0
	125 A	6	6	SK9801	72.00	#12-1/0
	150 A	6	6	SK9796BW	87.00	#8-3/0
	150 A	8	8	SK9797	93.00	#8-3/0
	40 A	2	2	QON2L40	23.30	#14-6 Cu, #12-6 Al
	70 A	2	4	QON24L70	33.60	#14-4 Cu, #12-3 Al
	1 Phase 3 Wire 240 Vac Max. 10,000 AIC	100 A	6	12	QON612L100	46.90
100 A		8	16	QON816L100	61.00	#8-1/0
100 A		12	12	QON12L100	75.00	#12-2/0
125 A		12	12	QON112L125I	80.00	#4-2/0
125 A		12	24	QON11224L125I	112.00	#4-2/0
125 A		16	16	QON116L125I	87.00	#4-2/0
125 A		16	24	QON11624L125I	127.00	#4-2/0
125 A		20	20	QON120L125I	150.00	#4-2/0
125 A		32	32	QON132L125I	240.00	#4-2/0
125 A		20	24	QON12024L125I	175.00	#4-2/0
150 A		24	24	QON124L150I	175.00	#4-250
200 A		12	12	QON112L200I	167.00	#4-250
200 A		24	24	QON124L200I	226.00	#4-250
200 A		30	30	QON130L200I	278.00	#4-250
3 Phase 3 Wire 240 Vac Max. 10,000 AIC (Without Neutral Assy.)	125 A	12	12	QON312L125	167.00	#4-2/0
	125 A	20	20	QON320L125	253.00	#4-2/0
	125 A	24	24	QON324L125	263.00	#4-2/0
	200 A	18	18	QON318L200	218.00	#4-300
	200 A	24	24	QON324L200	268.00	#4-300
200 A	30	30	QON330L200	318.00	#4-300	
225 A	42	42	QON342L225	449.00	#4-300	
3 Phase 4 Wire 240 Vac Max. 10,000 AIC	60 A	3	3	QON403L60N	33.20	#12-6
	125 A	12	12	QON312L125I	187.00	#4-2/0
	125 A	20	20	QON320L125I ▲	294.00	#4-2/0
	125 A	24	24	QON324L125I	307.00	#4-2/0
	200 A	18	18	QON318L200I	284.00	#4-300
	200 A	24	24	QON324L200I	312.00	#4-300
200 A	30	30	QON330L200I ▲	352.00	#4-300	
225 A	42	42	QON342L225I	477.00	#4-300	

6 CIRCUIT BREAKERS

**QO Plug-On Mounting Bases—For unit mounting QO, QO-GFI and QO-EPD circuit breakers**

1 Phase 2 Wire 240 Vac Max. 10,000 AIC (Without Neutral Assembly)	70 A	1	1	QOMB1	19.70	#14-4 Cu #12-2 Al
	70 A	2	2	QOMB2	39.00	#14-4 Cu #12-2 Al
	70 A	3	3	QOMB3	58.00	#14-4 Cu #12-2 Al

**QOB Bolt-On Mounting Bases—For unit mounting QOB, QOB-GFI, QOB-EPD circuit breakers**

3 Phase 3 Wire 240 Vac Max. 10,000 AIC (Without Neutral Assembly)	100 A	3	3	QON3B	37.60	#12-1
--	-------	---	---	-------	-------	-------

▲ Also IEC rated and CE marked for IEC 60439-1. Use only Square D Type QOXC, QOXD, QOHX and QOE circuit breakers for 415Y/24- Vac max. systems.

**Solid Neutral Assemblies**

Main Lug Rating	Number of Branch Neutral Terminals	Catalog Number	Price	Main Neutral Lug Wire Size AWG/kcmil	Branch Neutral Terminal Wire Size AWG	
				Cu/Al	Cu	Al
125	12	SN12125	\$24.20	#4-2/0	#14-4	#12-4
125	20	SN20	26.30	#4-2/0	#14-4	#12-4
200	12	SN12200	27.10	#4-300	#14-4	#12-4
200	30	SN30	35.90	#4-300	#14-4	#12-4
225	42	SN42	42.30	#4-300	#14-4	#12-4