



DATASHEET



SUR5LEDBK

230V IP20 45W LED Dual Mount Luminaire Matt Black

www.mlaccessories.co.uk

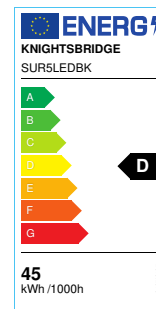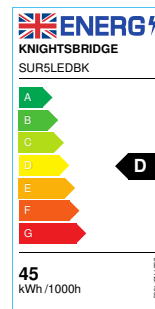

MLA PART CODE	SUR5LEDBK
DESCRIPTION	230V IP20 45W LED Dual Mount Luminaire Matt Black
NET WEIGHT (KG)	3.9
FINISH	Matt Black
DIFFUSER	Opal
DIMENSIONS (MM)	Length - 1500 Width - 200 Projection - 45
CONSTRUCTION	Construction - Pressed steel Construction 2 - & polypropylene
CLASS	I
IP RATING	IP20
WATTAGE (W)	45
LAMP TECHNOLOGY	SMD LED
LAMP INCLUDED	Yes
LUMENS (LM)	4200
LUMENS LIGHT SOURCE ONLY (LM)	6550
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	150
CIRCUIT WATTAGE (W)	43.7
CCT	4000K
LIGHT COLOUR	Cool White
CRI	>80
SDCM	<6
RUNNING CURRENT (A)	0.196
DISPLACEMENT FACTOR	>0.9
SVM	0
PST-LM	0
BEAM ANGLE (DEGREES)	110
L70B50 LIFESPAN (HRS)	50,000

DIMMABLE	No
OPERATING TEMPERATURE	25°C
INPUT VOLTAGE	230V 50Hz
CABLE ENTRY (MM)	20
CABLE GLAND INCLUDED	Blind grommet
DRIVER	DRIVER TYPE - Constant Current MAX. OUTPUT - 43W OUTPUT VOLTAGE - 30-40V OUTPUT CURRENT - 1080mA POWER FACTOR - 0.95 EFFICIENCY FULL LOAD - 88.7 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~50°C CASE TEMPERATURE (Tc) - 75°C
WARRANTY	5year(s)
MANUFACTURED IN ACCORDANCE WITH	BS 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5061061275221

Date Created: 26/06/2025 11:07

