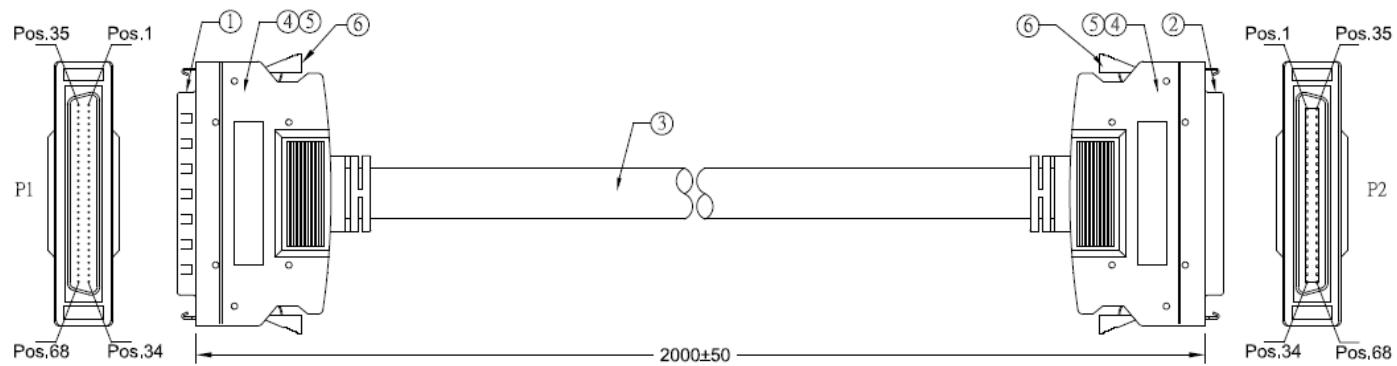
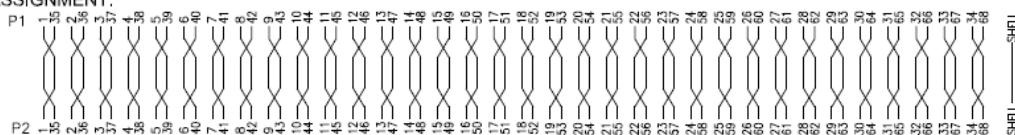


Product Datasheet**SCSI Ultra 320 HPDB68 M/F****Cable 2m, latch type****RS Stock No. 8011187****ELECTRICAL SPECIFICATIONS**

1. Rating: Temp 80°C Voltage 30V
2. Conductor Resistance: AT 20°C MAX.
30AWG:376.96. Ω /KM
3. Impedance Resistance: 10M Ω /km mln
at 20°C dc 500V
4. Dielectric Strength: AC 500V/1 minute.

SPECIFICATION


PIN ASSIGNMENT:


ITEM	QTY	U/M	PART NO.	DESCRIPTION
6	4	EA	FLLD68BKNIP140001	Latch A4 Type, Color : Black
5	/	MM	SFC3010001	Copper Foil 360° Soldered
4	/	KG	DBPVCNU040BK01001	Molded 40P PVC Color:Black(BK01).
3	1	EA	W291930BK34PB0000M01	UL2919 30AWG 34TW/PR,Al/Mylar+Drain +Braid, Color:Black(BK01).
2	1	EA	CHPDB068FBK10U000104	HPDB68 Female, Pitch1.27mm, Shell:Tin Plated Contact:Gold 10U",Insulation:Black,PBT UL94V-0
1	1	EA	CHPDB068MBKTIN000024	HPDB68 Male, Pitch1.27mm, Shell: Tin Plated Contact:Gold 10U",Insulation:Black,PBT UL94V-0

Package:

1pcs/PE bag

