


**Item # 70-782EL14-1, 70-782EL14-1 Socket / 10 Amp Rating, 300 Volts**

14 Pin Ice Cube, Logic Style, DIN Panel Mount with Elevator Terminals, Module Compatible.

This Item is Normally Stocked

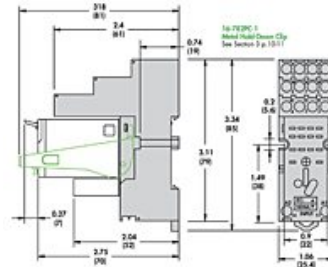

[Specifications](#) · [Electrical Rating](#) · [Temperature](#) · [Construction](#) · [Miscellaneous](#) · [Product Certifications](#)

**Specifications**

Check Inventory	<a href="#">Check Distributor Inventory</a>
Contact Configuration	4PDT
Number of Terminals	14
Mounting Style	DIN Rail Panel

**Electrical Rating**

Current Rating	10 A
Nominal Voltage Rating	300 V

**Temperature**

Storage Range	- 40 to + 105 °C
---------------	------------------

**Construction**

Protection Category (Finger Safe)	IP 20
Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Steel Zinc Plated
Screw Style	Combination Head
Screw Size	M3 mm
Screw Torque 3 mm (Maximum)	7 / 0.8 Lb-in / Nm
Terminal Connection	Elevator
Terminal Layout	Logic
Base	Square

**Miscellaneous**

<b>Wire Size Capacity (Maximum), EN 60204-1, Solid Cu</b>	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm <sub>2</sub>
<b>Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu</b>	14 / 16 (2) AWG, 2.5 / 1.5 (2) mm <sub>2</sub>
<b>DIN Rail Mounting, EN 60715</b>	35 mm
<b>Chassis Mount Screw Torque</b>	7 / 0.8 Lb-in / Nm
<b>Flammability Rating</b>	94V-0 Class
<b>Body Color</b>	Light Gray
<b>DIN Locking Method</b>	Red Plastic Locking Clip

---

**Product Certifications**

<b>Agency Approvals</b>	CE RoHS UL CSA
-------------------------	-------------------------