

RS Pro Datasheet – Fiche Technique – Datenblatt


RS Pro: 144-8592




VALUE USB 2.0 Cable, A - B, M/M, 4.5 m

VALUE Câble USB 2.0 Type A-B, 4.5m

VALUE USB 2.0 Kabel, Typ A-B, 4,5m

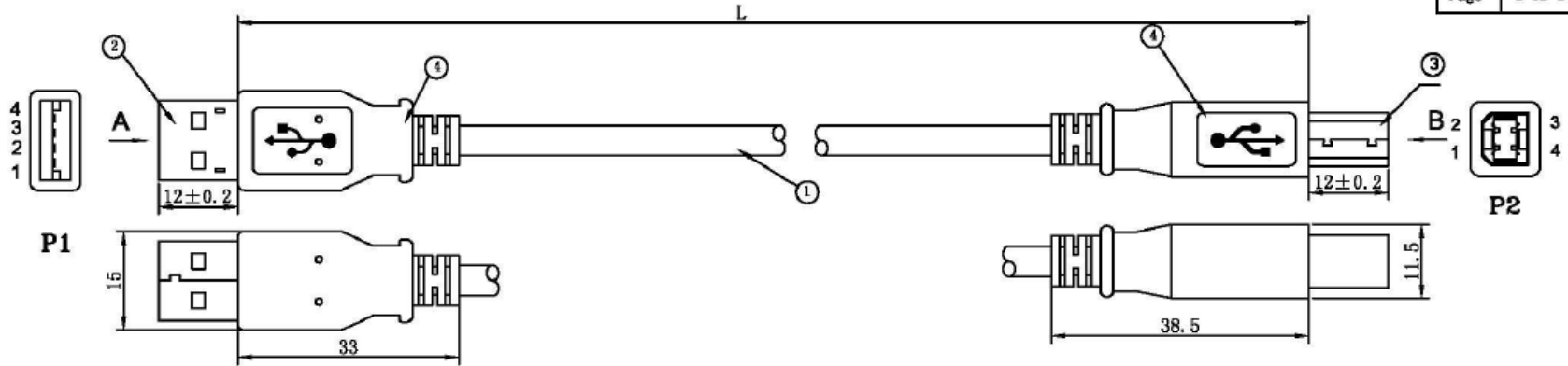

PIN OUT

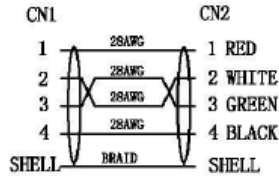

NOTE:

ITEM NO	LENGTH
11.99.8809	800mm
11.99.8819	1800mm
11.99.8831	3000mm
11.99.8841	4500mm

NOTE:

- Electrical test:
 - 100% open short & miss wire test;
 - Insulation resistance:DC 300V 10M Ω;
 - Contact resistance:3Ω Max;
 - Dielectric strength:100V AC/Minute, 1mA.
- RoHS & REACH compliant
- PRINTING:USB 2.0 CABLE, 28AWG×1P+28AWG×2C
- Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON

MATERIAL LIST:

④	OUTER MOLD	Shore 88A PVC(UL94V-2) Color: White	2	
③	USB B TYPE	USB B /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1	
②	USB A TYPE	USB A /M Type, The Pin Gold Plating 30U", the shell for Nickel Plating	1	
①	CABLE	USB 2.0 28AWG (7/0.12BC*1P)+28AWG (7/0.12BC*2C)+AB B=0.12/3*16 AL-MG JACKET:PVC/WHITE OD: 4.0mm, Braid Coverage: 48%	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT'Y	REMARK

		CUSTOMER	RT	REF.	ITEM NO.	See The Chart	
		PRODUCT NAME	VALUE USB 2.0 Cable, AM/BM			UNTT	MM
		DRAWNBY	CHECKBY	APPOBY	DATE		
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.	Elaine	2011-08-02	