


Sealing cap - PROT-M12 FS-M-CHAIN - 1430491

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

M12 sealing cap made of metal with fixing chain, for free M12 plugs with chain and 16.0 mm fastening eye



Key Commercial Data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 046356 325783
GTIN	4046356325783
Weight per Piece (excluding packing)	13.410 g
Custom tariff number	74199990
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

Ambient conditions

Ambient temperature (operation)	-40 °C ... 85 °C
Degree of protection	IP65
	IP67
	IP69K

General

Note	Use up to max. 48 V AC and 60 V DC
------	------------------------------------

Material

Material	CuZn/Ni
Sealing material	NBR
Additional material specifications	CuZn/Ni (Chain)

Environmental Product Compliance

Sealing cap - PROT-M12 FS-M-CHAIN - 1430491


Technical data

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

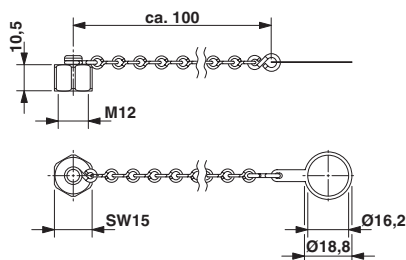

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260700
eCl@ss 6.0	27379200
eCl@ss 7.0	27379218
eCl@ss 8.0	27379218
eCl@ss 9.0	27379218

ETIM

ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002040
ETIM 6.0	EC002040

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31251501

Sealing cap - PROT-M12 FS-M-CHAIN - 1430491

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.01742
-----	---	---------
