


Features

- Heavy duty textile material 1680D/600D polyester
- Pockets and elastic strap for tools
- Padded back laptop compartment: 16-20 inch
- Multi-purpose tool compartment
- Square reinforced PP bottom keeps the case stable and vertical and provide protection against wet floor
- High-density foam back padded straps
- Adjustable padded chest and stomach belt
- Document and Laptop holder
- Touch ladder attachment system
- Polypropylene compartment: waterproof protection
- Lockable zips
- Ergonomic handle
- A rich variety of tools meet the daily usage needs of engineers.
- CR-V materials tools support efficient duty work
- Exquisite color box packaging in backpack

RS PRO 37pcs tool Kit backpack

RS Stock No.: 606-515

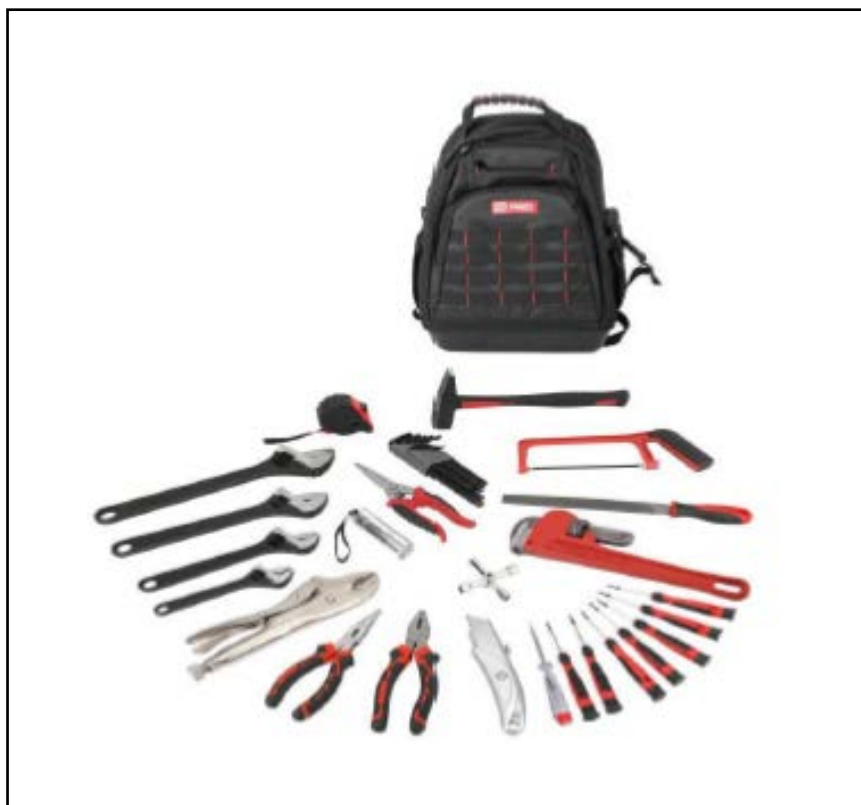

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO 37pcs tool Kit backpack

RS PRO Backpack is designed for Technicians who prefer a textile tool storage system as an alternative to a toolbox or tool case. This tool bag combines multiple storage areas into one to create comprehensive tools and documents storage system. This tool backpack is well thought out, offers plenty of pockets, holders and zipped compartments.

This bag offers a host of additional features that set it apart from typical tool bags. The base is completely waterproof so no fear of damage in wet conditions, open the main compartment and insider there is a pullout compartment that stands vertically on flat surfaces perfect for test equipment, screwdriver, spanners, and other tools.

Backpack tool bag with wide zipper opening for easy tool access from the large compartment. This backpack is equipped with 6 external pockets and 16 internal pockets and 6 elastic loops for tons of tool storage, including laptop sleeve for holding laptops up to 14 inches. Mesh covered contact surface areas enable efficient air circulation between the backpack and your back. Rubbers handle for carrying comfort. Square reinforced PP bottom keeps the case stable and vertical and provide protection against wet floor.

The ultimate key feature is the additional back and shoulder support. This feature, when attached around the waist, adds support and distributes weight more evenly across the back so it's much easier to carry around during longer periods of time.

Feature and Benefits

- Heavy duty textile material 1680D/600D polyester
- Pockets and elastic strap for tools
- Padded back laptop compartment: 16-20inch
- Multi-purpose tool compartment
- Square reinforced PP bottom keeps the case stable and vertical and provide protection against wet floor
- High-density foam back padded straps
- Adjustable padded chest and stomach belt
- Document and Laptop holder
- Touch ladder attachment system
- Polypropylene compartment: waterproof protection
- Lockable zips

- Ergonomic handle
- Capacity: 33L
- Weight: 2.89 kg

Max load: 20kg

Tools set details

Precision Screwdrivers (Red and Black Handles): 1.5; 2.5; 3; 3.5, PH00; PH0; PH1. CRV heads are blackened and magnetized.

LED flashlight (black) (battery not provided), with 9 lamp beads.

13pcs L Shape Hex Key Set (gray slot): 1.27, 1.5, 2, 2.5, 3, 3.5, 4, 4.5, 5, 5.5, 6, 8, 10

160mm Needle-nose Pliers, CS heat, red and black handles

160mm Wire Cutters, CS heat, red and black handles

205mm Garden Pruning Shears, SS, red and black handles

254mm Locking Pliers, CRV

300g Bench Hammer, red and black handles, PP + TPR, CS, hot forged with steel die

305mm (12inch) Pipe Wrench, CS, forged, American style, red, made of 45# carbon steel, handle is ductile iron

200mm File, red and black handles, CS

150mm Hacksaw Frame, red and black handles, with 18tpi saw blade made of 65mn steel,

4-piece set

6"/8"/10"/12" Adjustable Wrench, CRV

3m Measuring Tape, imperial system, red and black

Zinc Alloy Sink Key, zinc alloy, chrome-plated, with a square hole in the middle.

Specifications: 9mm triangle, 5mm circle; 9mm square hole; 6mm square hole.

75mm Electrical Tester (CE), 100 - 250V

Utility Knife, silver, 60mm retractable blade, 80g, made of aluminium alloy

General Specifications

Material	Nylon, PVC, PP, TPR, Zinc, CRV, CS, ABS
External Dimensions	380 x 220 x 520 mm
Foam	No
Wheels	No
Colour	Black, Red
Material Type	Nylon, PVC, PP, TPR, Zinc, CRV, CS, ABS
Lockable	No
Dividers	No
Net Weight	8.2 kg

Mechanical Specifications

Loading Capacity

Up to 20 kgs





7pcs Slotted Precision Screwdriver Set/LED Torch/12pcs Hex Key Set/Long Nose / Combination Pliers / Straight Tin Snips/Locking Pliers/4pcs Pipe Wrench/Flat Engineers File/Hacksaw/ Bench Hammer /3m Tape Measure/ 5-way Control Cabinet Key/Tester Screwdriver/ Safety Knife

