



Model No.DFN350 35MM CORDLESS BRAD NAILER

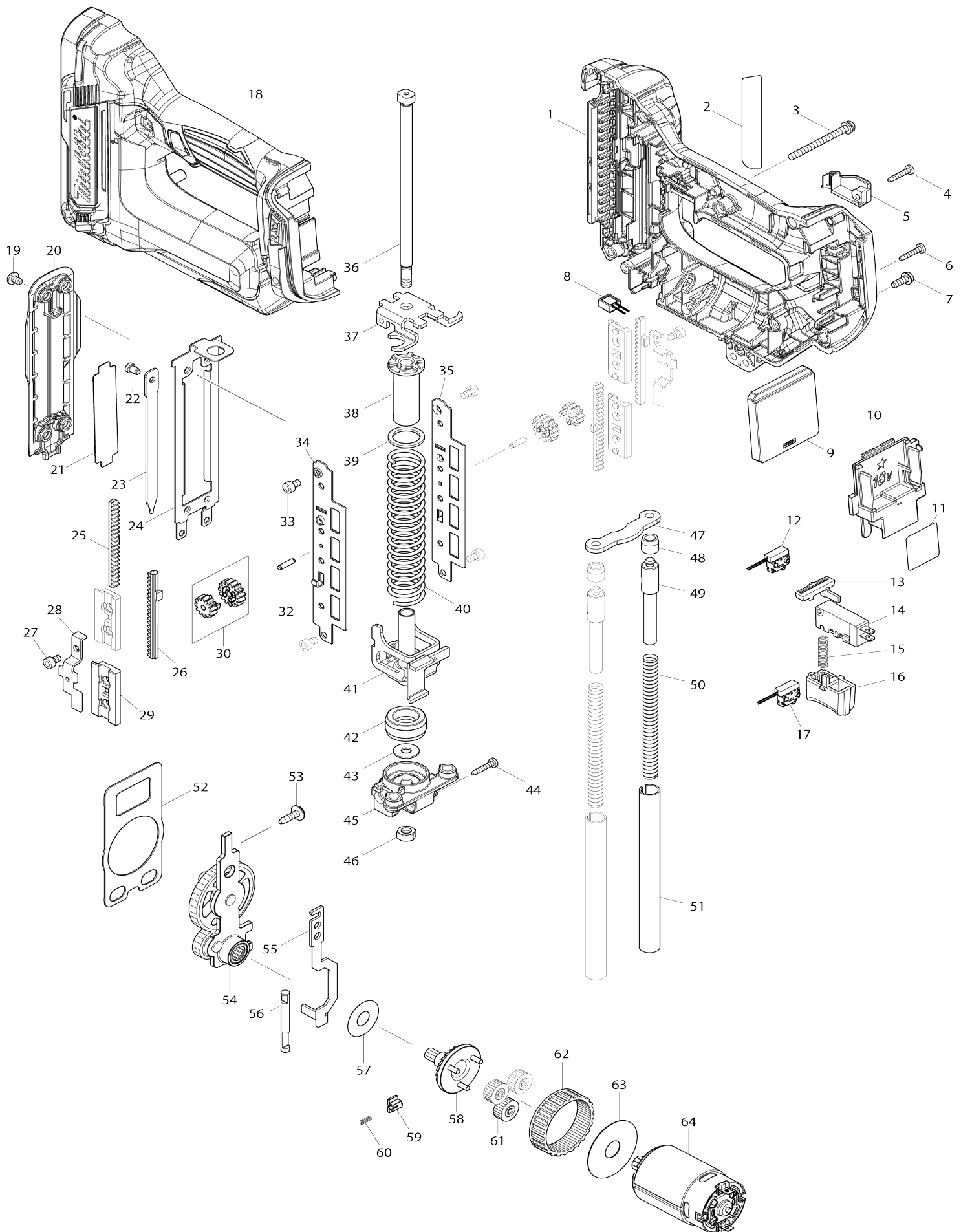

Model No.DFN350 35MM CORDLESS BRAD NAILER

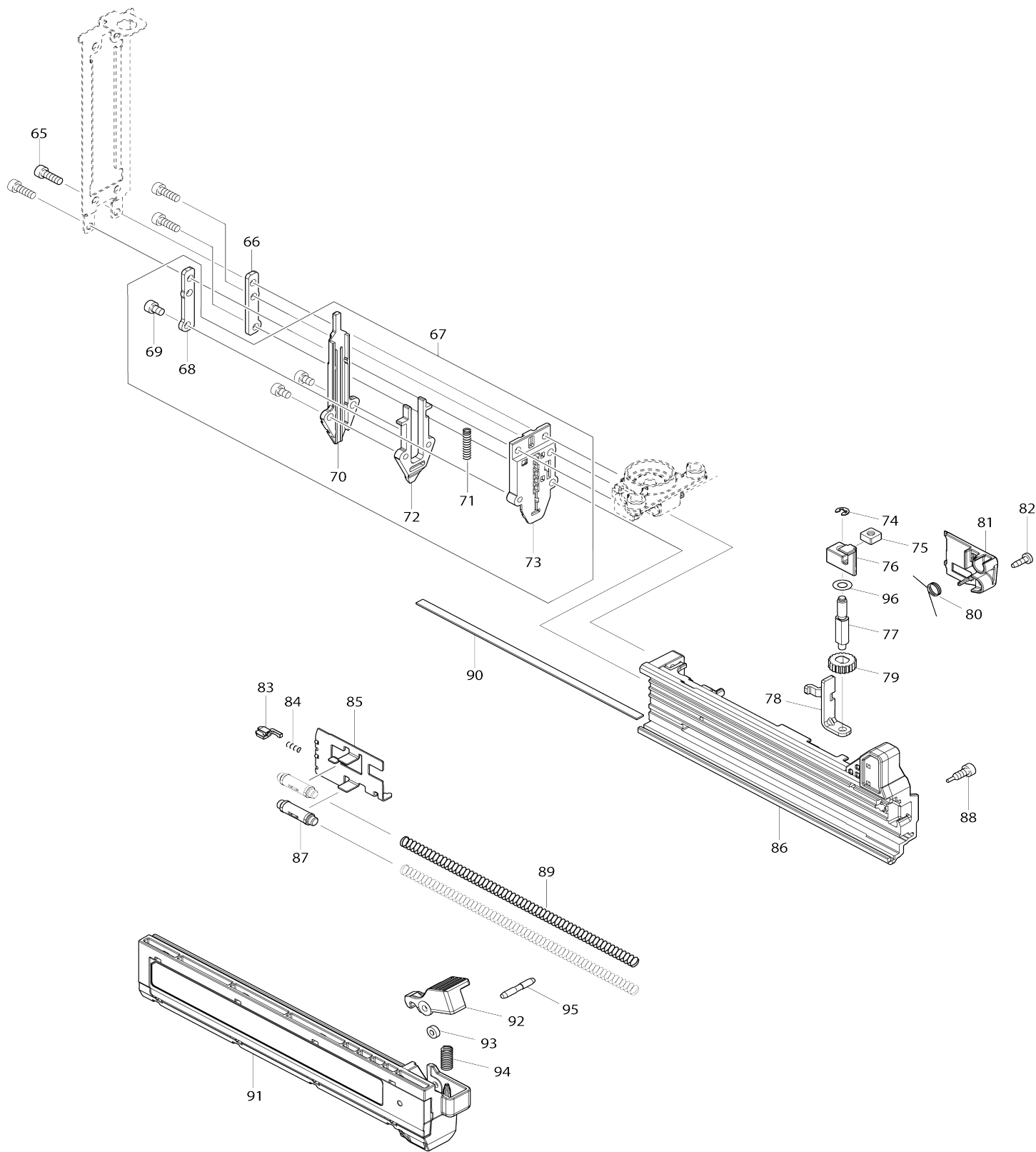

Model No.DFN350 35MM CORDLESS BRAD NAILER

Item No.	Parts No.	Description	Interc hang eabilit y	Q'ty	New/ Old	Note1	Note2
001	183L67-6	HOUSING SET		1	*		
C10	263005-3	RUBBER PIN 6		2	*		
C20	252126-6	HEX. LOCK NUT M4-7		2	*		
C30	931102-0	HEX. NUT M4		1	*		
001		INC. 18			*		
001-1	183L68-4	HOUSING SET	S	1			
C10	263005-3	RUBBER PIN 6		2			
C20	252126-6	HEX. LOCK NUT M4-7		2			
C30	931102-0	HEX. NUT M4		1			
001-1		INC. 18					
002	855T69-7	DFN350 NAME PLATE		1			
003	911173-3	PAN HEAD SCREW M4X45		1			
004	266130-9	TAPPING SCREW BIND PT 3X16		1			
005	457385-9	HOUSING R COVER		1			
006	266130-9	TAPPING SCREW BIND PT 3X16		8			
007	911118-1	PAN HEAD SCREW M4X12		2			
008	620507-6	LED CIRCUIT		1			
009	632N38-7	CONTROLLER UNIT		1			
010	643860-3	TERMINAL		1	*		
010-1	643874-2	TERMINAL	S	1			
011	855T76-0	DFN350 SERIAL NO. LABEL		1			
012	632G60-2	SWITCH UNIT		1			
013	456799-9	TRIGGER LOCK		1			
014	651910-0	SWITCH D2VW-01-3HS		1			
015	232370-1	COMPRESSION SPRING 5		1			
016	457386-7	TRIGGER		1	*		
016-1	412772-9	TRIGGER	<	1			
017	632K06-2	SWITCH UNIT		1			
018	183L67-6	HOUSING SET		1	*		
C10	263005-3	RUBBER PIN 6		2	*		
C20	252126-6	HEX. LOCK NUT M4-7		2	*		
C30	931102-0	HEX. NUT M4		1	*		
018		INC. 1			*		
018-1	183L68-4	HOUSING SET	S	1			
C10	263005-3	RUBBER PIN 6		2			
C20	252126-6	HEX. LOCK NUT M4-7		2			
C30	931102-0	HEX. NUT M4		1			
018-1		INC. 1					
019	915101-0	BINDING HEAD SCREW M4X6		4			
020	459369-3	FRONT COVER		1			
021	347528-0	UPPER PLATE		1			
022	256882-0	FLAT FILLISTER HD. PIN 4		1			
023	347519-1	DRIVER		1			
024	347521-4	RAIL		1			
025	310924-5	COUNTER WEIGHT A		2	*		
025-1	313421-0	COUNTER WEIGHT A	<	2	*		
025-2	313665-2	Counter weight A	O	2			

026	310925-3	COUNTER WEIGHT B		2			
027	251566-5	H.S.H BOLT M4X6 WITH W		2			
028	347146-4	PINION GUIDE		2			
029	457390-6	COUNTER WEIGHT HOLDER		4	*		
029-1	413330-4	COUNTER WEIGHT HOLDER	O	4			
030	136104-3	SPUR GEAR ASSEMBLY		2			
032	326902-5	PINION SHAFT		2			
033	266199-3	HEX.SOCKET HEAD BOLT M4X6		4			
034	347145-6	GUIDE RAIL R		1			
035	347144-8	GUIDE RAIL L		1			
036	326903-3	GUIDE BOLT		1			
037	347526-4	BOTTOM PLATE		1	*		
037-1	347728-2	BOTTOM PLATE	S	1			
038	459311-4	SPRING HOLDER		1			
039	347522-2	SPRING BASE		1			
040	232511-9	COMPRESSION SPRING 17		1			
041	347524-8	HAMMER		1	*		
041-1	347657-9	HAMMER	<	1	*		
041-2	347735-5	HAMMER	S	1			
042	422457-9	CUSHION		1	*		
042-1	422D00-8	CUSHION	O	1			
043	253804-1	FLAT WASHER 6		1			
044	266130-9	TAPPING SCREW BIND PT 3X16		1	*		
045	319824-6	HOLDER		1	*		
045-1	319965-8	HOLDER	<	1			
046	252273-3	HEX. NUT M6		1			
047	347527-2	COUNTER STOPPER		1	*		
047-1	347729-0	COUNTER STOPPER	S	1			
048	422456-1	COUNTER CUSHION		2	*		
048-1	422592-3	COUNTER CUSHION	S	2			
049	326904-1	WEIGHT		2	*		
049-1	327591-9	WEIGHT	S	2			
050	232363-8	COMPRESSION SPRING 7		2			
051	327328-4	GUIDE PIPE		2	*		
051-1	327592-7	GUIDE PIPE	S	2			
052	347525-6	GEAR PLATE		1			
053	266901-4	TAPPING SCREW 4X14		1			
054	140K45-3	SPUR GEAR 61 COMPLETE		1	*		
054-1	140Y96-0	SPUR GEAR 61 COMPLETE	<	1			
055	347139-1	LOCK ARM		1			
056	327327-6	LOCK PIN		1			
057	253353-8	THIN WASHER 10		1			
058	140K48-7	SPUR GEAR 8 COMPLETE		1			
059	310945-7	LOCK BLOCK		1			
060	232513-5	COMPRESSION SPRING 3		1			
061	221961-3	SPUR GEAR 27		3			
062	227166-3	INTERNAL GEAR 69		1			
063	267053-4	FLAT WASHER 12		1			
064	629408-5	DC MOTOR		1			
065	922117-8	HEX. SOCKET HEAD BOLT M4X12		4	*		
065-1	922127-5	HEX. SOCKET HEAD BOLT M4X16	S	2			
066	347523-0	PLATE		1			

067	127291-9	DRIVER GUIDE ASSEMBLY		1			
067		INC. 68-73					
068	347523-0	PLATE		1			
069	922102-1	HEX. SOCKET HEAD BOLT M4X6		3			
070	310942-3	DRIVER GUIDE		1			
071	232512-7	COMPRESSION SPRING 3		1			
072	310943-1	CENTER PLATE		1			
073	310941-5	SET PLATE		1			
074	961017-7	STOP RING E-3		1			
075	264050-1	SQUARE NUT M5-8		1	*		
075-1	264050-1	SQUARE NUT M5-8	S	1			
076	459309-1	CONTACT ARM		1	*		
076-1	412237-1	CONTACT ARM	<	1	*		
076-2	412726-6	CONTACT ARM	S	1			
077	327326-8	ADJUSTER SHAFT		1			
078	347529-8	ARM		1			
079	459310-6	ADJUSTER		1			
080	232514-3	TORSION SPRING 7		1			
081	459312-2	ADJUSTER COVER		1			
082	266007-8	TAPPING SCREW BIND PT 3X10		1			
083	310176-8	STOPPER		1			
084	233018-8	COMPRESSION SPRING 3		1			
085	347520-6	PUSHER		1			
086	459305-9	MAGAZINE		1			
087	459313-0	SLEEVE		2			
088	265A52-6	HEX.SOCKET HEAD BOLT M4X14		1			
089	234325-2	COMPRESSION SPRING 6		2			
090	346774-2	NAIL PLATE		1			
091	140K97-4	SLIDE DOOR COMPLETE		1			
092	457388-3	LEVER		1			
093	262054-7	URETHANE RING 3		1			
094	233117-6	COMPRESSION SPRING 6		1			
095	256877-3	PIN 3		1			
096	253334-2	THIN WASHER 5		1	*		
096-1	267010-2	FLAT WASHER 5	S	1			
097	922117-8	HEX. SOCKET HEAD BOLT M4X12	S	2			
A02	251314-2	+ TRUSS HEAD SCREW M4X12		1			
A03	346317-0	HOOK		1			
A04	422464-2	NOSE ADAPTER		1			
A05	783201-2	HEX. WRENCH 3		1			

Please state Parts No. when your order.

Print Date 05/30/2025