


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150390211](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 6 Circuits

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification PS-15039-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-15039-001-001 (PDF)	

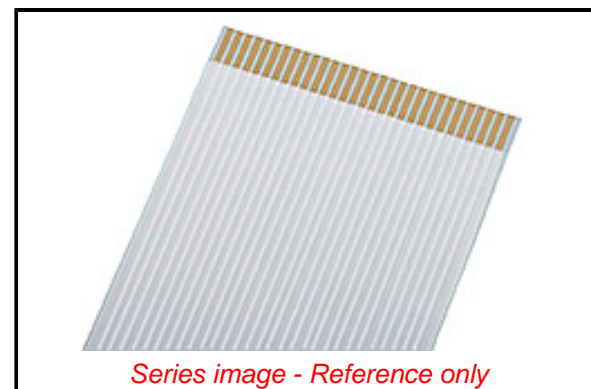

Series image - Reference only

General

Product Family	Cable
Series	15039
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	193264173952

Physical

Cable Length	152.00mm
Circuits (Loaded)	6
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	0.870/g
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical

Current - Maximum per Contact	1.2A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-15039-001-001
Product Specification	PS-15039-001-001
Sales Drawing	SD-15039-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15039 Series

Mates With

Easy-On FFC/FPC Connector:

[522070660](#) , [522710669](#) , [526100672](#) ,
[2005280060](#) , [2005280061](#)