
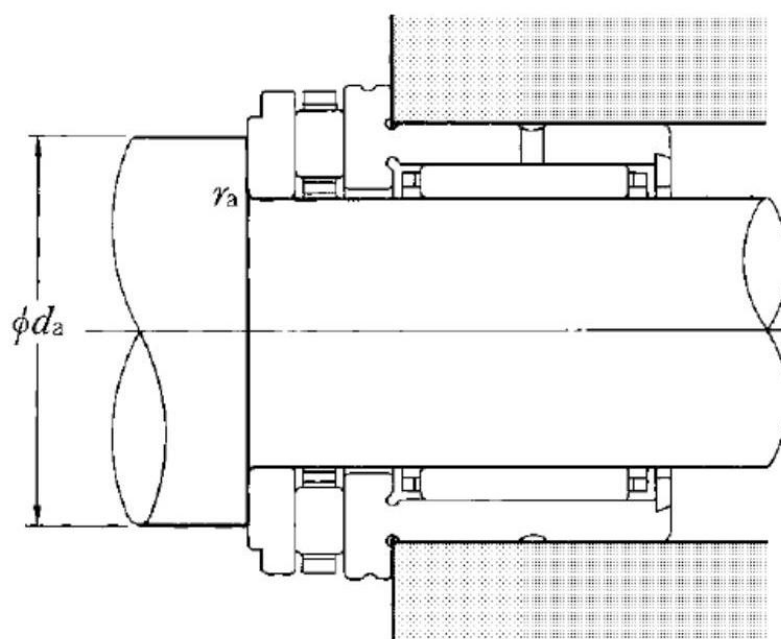
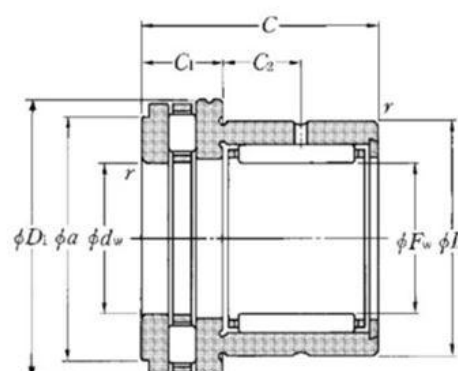


Technical data

NKXR15T2Z

Combined bearings

VISUAL (S)

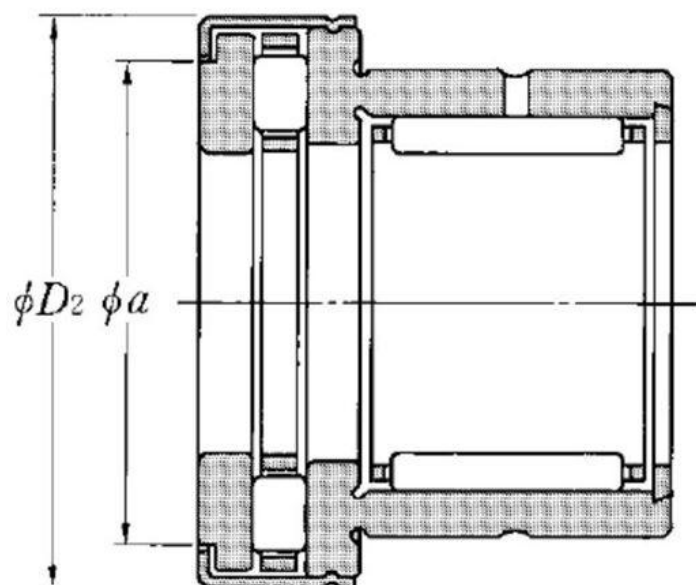

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	15 mm
dw - Shaft washer bore diameter	15 mm
D - External diameter	24 mm
D2 - Thrust bearing external diameter	29 mm
C - Width of bearing, drawn cup or outer ring	23 mm
C1 - Thrust bearing height	9 mm
C2 - Hole location	6,5 mm
a - Thrust bearing support diameter	23,7 mm
rs - Min fillet radius	0,3 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Precision class	P0
Mass	0,052 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	8,25 kN
Ca - Dynamic axial load rating	12,9 kN
C0r - Static load rating	10,2 kN
C0a - Static axial load rating	28,6 kN
N lim - Grease lubrication limit speed	2800 tr/min
N lim - Oil lubrication limit speed	11000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C



ABUTMENT

da min - Min shoulder diameter IR	25 mm
ras max - Max shaft & housing fillet radius	0,3 mm

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	NKXR15T2Z
Image	NRBNKXR_Z_1.jpg, NRBNKXR_Z_2.jpg, NRBNKXR_Z_3.jpg
Rolling element material	Acier 100Cr6

