


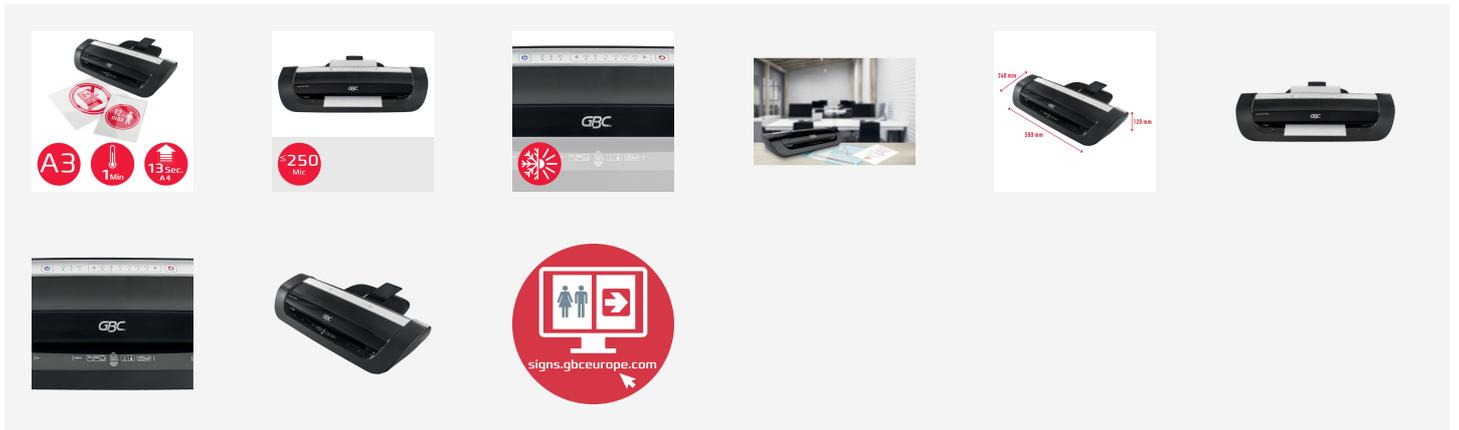

GBC Fusion Plus 7000L A3 Laminator

Professional quality, accelerated productivity. Super-fast and easy to use, ideal for heavy use in the busy office or education environment. Next generation intelligent input sensor technology gauge the precise thickness of the pouch and contents and automatically adjusts throughput speed, with manual override for non-standard media. Laminate using light-weight 2x75 up to heavy weight 2x250 micron thermal pouches . The result is a flawless finish.



Attributes

- A3 laminator
- Warms up in 1 minute
- Laminates an A3 document in less than 13 seconds using a 2x75 micron pouch
- Laminates from ID to A3 size
- Next generation Intelligent input sensors automatically adjust speed for a flawless finish
- Manual over-ride for non-standard media
- Intelligent auto reverse prevents pouch misfeeds or jams
- High speed laminating machine
- 6-roller technology for ultra fast high quality lamination
- 2-year warranty
- For best results use with GBC document pouches

Specifications

Number	4402133
Colour	-----
Dimensions (W x H x D)	578 x 121 x 235 mm
Laminating Speed (mm/min)	1400
Power Supply	220/240 V AC
Warm up Time (min)	1
Heating System	4 heated rollers
Operation Mode	6 roller technology, no carrier, speed controlled
Max. Laminating Width (mm)	303
Max. Laminating Thickness (mm)	1.0
Max. Pouch Thickness (microns)	250
Power Consumption (W)	1450
Dimensions (with Tray) mm	580(W) x 120(H) x 330(D)
Anti-Jam Technology	Auto & Manual Reverse
Approx. lamination time (A4)	13 secs (A4 75 microns)
Photo friendly	Yes
Period of Warranty (Years)	2
Type	Pouch
Weight	8190 g
Pallet quantity	15
EAN code	5028252515467