

## Lowbay 400w Metal Halide LBY400MH


### General Information

Economy lowbay luminaire suitable for mounting as low as 4 metres. A wide range of attachments available making it suitable for heavy and light manufacturing, assembly shops, warehousing facilities as well as sports and leisure centres.

- High quality F Marked luminaire.
- Supplied complete with lamp, toughened glass and timed ignitor as standard.
- Aluminium reflector and body suitable for multi attachments - see related items.
- Suitable for direct fixing to ceiling or trunking, BESA box mounting and conduit or chain suspension.
- Detachable hinged geartray for simple installation and maintenance.



Lowbay

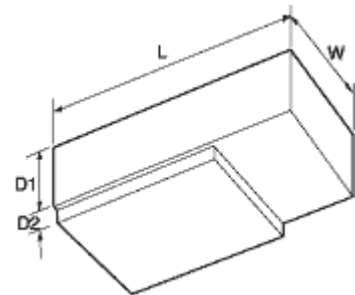

### Specification

Brand:	<i>Crompton</i>
Dimensions (mm):	<i>L 600 x W 318 x D 184</i>
Weight (KG):	<i>13.4</i>
ANA Number:	<i>5018986224117</i>
Cable Entry:	<i>Rear</i>
Lamp Wattage (W):	<i>400</i>
Lamp Length/Type:	<i>Metal halide elliptical</i>
IP Rating:	<i>IP20</i>
No. of Lamps:	<i>1</i>
Circuit Type:	<i>MBF</i>
Total Circuit Watts (W):	<i>431</i>
Total VA:	<i>501</i>