


## Datasheet

### Telephone Slide LED Indicator Lamp

RS Stock number 204-344

#### Dimensions (mm):

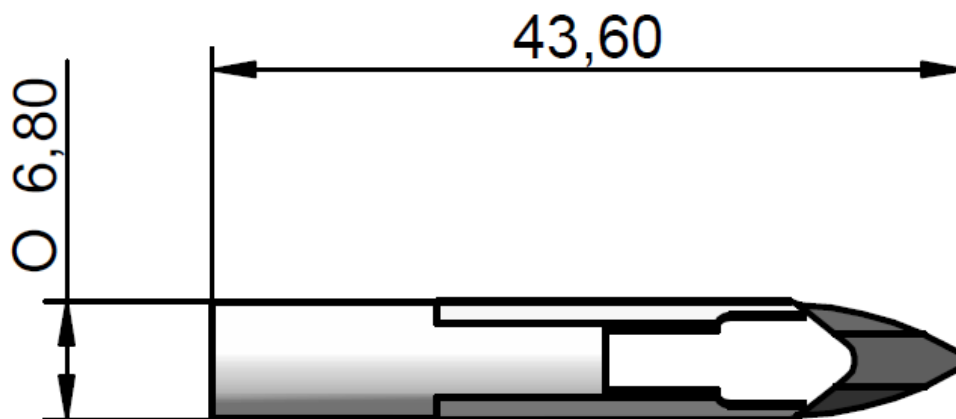

#### Specifications:

LED/Multiled	LED
Mounting Size	T6.8
Mounting Finish	-
Protection	-
Mount Holder	T6.8
Chip Qty	1
Indicator Colour	White
Optimum Voltage (V)	48V dc
Rectifier	-

AC Current	-
DC Current	15mA
Voltage Tolerance	10%
Optimum Temperature	-30°C ... +60°C
Storage Temperature	-30°C...+60°C
Contact Tab x 2	T6.8 Slide Base
Wavelength (nm)	-
Intensity	1500mcd
Reverse Voltage	-