


KEMET Part Number: HHBC13-1R2A0081V
(UALC131R2A0081)

KEMET, HHBC, AC Line Filters, Normal Mode, 81 uH, 20%

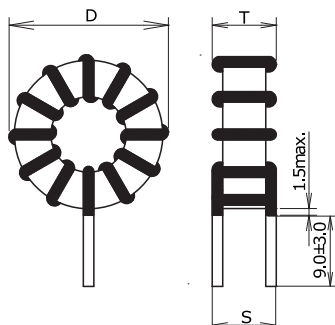

Dimensions

D	30mm MAX
T	15.7mm MAX
LL	9mm +/-3mm
S	11mm NOM

Packaging Specifications

Packaging:	Tray
Packaging Quantity:	150
Weight:	26 g

General Information

Series:	HHBC
Style:	Through-Hole
Features:	Noise Solution, Switching Power Supply Outlets, DC-DC Converter
RoHS:	Yes
Miscellaneous:	30 (K) Temperature Rise Max.

Specifications

Inductance:	81 uH
Inductance Tolerance:	20%
Current:	6 A
Temperature Range:	-40/+125°C
DC Resistance:	24.7 mOhms