


# manifold block MHA4-PR4-3-1/4

Part number: 525235

FESTO

For sub-base valves MHA4-...

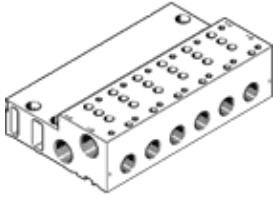

## Data sheet

Feature	Value
Max. number of valve positions	4
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Product weight	750 g
Mounting method for sub-base	with through hole with top-hat rail
Mounting method for valve	with internal (female) thread
Pneumatic ports 1/33	G3/8
Pneumatic connection, port 2	Female thread 1/4
Pneumatic ports 3/11	G3/8
Materials note	Free of copper and PTFE
Material of connecting plate	Wrought Aluminium alloy