


FX0430/PC Datasheet

Product Name // Fuseholder FX0430 Series Protection
Category PC3 PCB Mount Snap Fit To Panel 5mm x 20mm
Fuse Captive Drawer Carrier

[View Product Page](#)

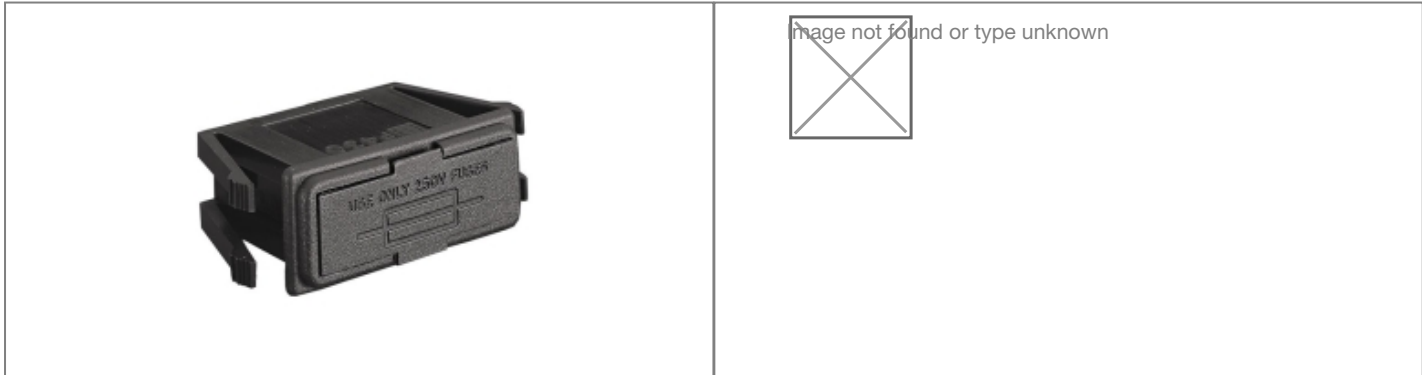

// Product Description:

- Protection Category PC3 Fuseholder
- 5mm x 20mm Captive Drawer fuse carrier
- Snap Fit To Panel mounting; 1mm, 1.5mm, 2mm, 3mm panel thickness, depending on part code
- Choice of Termination depending on part code: /28 - 2.8mm Solder Tag, /48 - 4.8mm Tab, /63 - 6.3mm Tab, /PC - PCB Spills

// General Information:

| | |
|--|--|
| Product Display Title: | Protection Category PC3 Fuseholder |
| Product Family: | Fuseholders |
| Product Series: | Panel/PC Mounting Captive Carriers Touchproof, PC3 |
| Approvals: | CSA, UL, VDE, IMQ |
| Body Material: | Nylon 66 |
| Current Max: | 10A, 16A |
| Flamability Rating: | UL94V-0 |
| Function: | Pc3 Fuseholder |
| Fuseholder Protection Category: | PC3 |
| Fuse Carrier: | Captive Drawer |
| Fuse Size: | 5mm x 20mm |
| Max Operating Temperature: | +85°C |
| Min Operating Temperature: | -20°C |
| Voltage Max: | 250V |

// Product PDF Links

[Fuseholders product data](#)

// Product 3D CAD Model Links

[FX0430/PC3D CAD Model](#)