




Product data sheet

Power tools for trade & industry

Table Saw

PRO GTS 18V-70

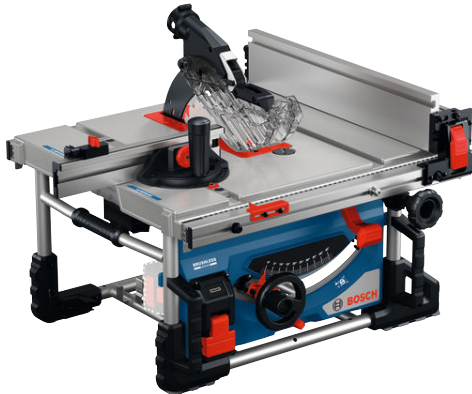

Compact cordless table saw with best-in-class cutting height

The most important data

Saw blade diameter	216 mm
Incline setting	47 ° L / -2 ° R
Table size	593 x 494 mm

Part Number 0 601 B44 100

Technical data

Technical data

Battery voltage	18.0 V
Table size	593 x 494 mm
No-load speed	5,500 rpm
Saw blade diameter	216 mm
Weight	21.2 kg
Max. cutting capacity on the right	635 mm
Packaging dimensions (width x length x height)	608 x 593 x 329 mm
Tool dimensions (width x length x height)	608 x 593 x 329 mm
Saw blade bore diameter	30 mm
Incline setting	47 ° L / -2 ° R
Max. cutting capacity on the left	305 mm
BITURBO	No
Cutting height 90°	70 mm
Cutting height 45°	49 mm

**BOSCH**

Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Highly portable thanks to cordless freedom with best-in-class cutting height of 70 mm
- Ensures precision cutting thanks to rack & pinion rip fence system and precise miter gauge
- Minimizes dust with two Click & Clean dust ports
- Convenient clampzone areas to fix workpieces to the tabletop

**HEAVY
DUTY**

0°/70 mm



-2°-47°



PRECISION



2x

BRUSHLESS
MOTOR

BRAKE SYSTEM

Click &
Clean
System

MITER GAUGE

PROFESSIONAL
18V
SYSTEM

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

