


## Technical data


GS81104

Thrust washer

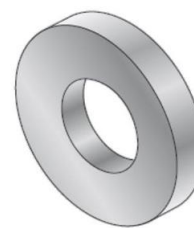

Needle roller bearing, thrust needle roller bearing, outer ring

### VISUAL (S)

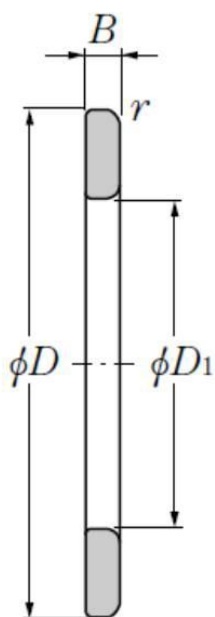

### PRODUCT DEFINITION

|                                                |          |
|------------------------------------------------|----------|
| Brand                                          | NTN      |
| D - Outside diameter of support washer OR - GS | 35 mm    |
| D1 - Bore diameter bearing washer OR - GS      | 21 mm    |
| B - Ring thickness                             | 2,75 mm  |
| rs - Min fillet radius                         | 0,3 mm   |
| Bearing ring (outer ring) GS mass              | 0,014 kg |

### PRODUCT PERFORMANCE

|                                  |        |
|----------------------------------|--------|
| Tmin - Min operating temperature | -20 °C |
|----------------------------------|--------|



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

**PRODUCT PERFORMANCE**

|                                         |        |
|-----------------------------------------|--------|
| <b>Tmax - Max operating temperature</b> | 120 °C |
|-----------------------------------------|--------|

**ESHOPDONOTDISPLAY**

|                  |         |
|------------------|---------|
| <b>Tracepart</b> | Oui/Yes |
|------------------|---------|

|                  |         |
|------------------|---------|
| <b>Reference</b> | GS81104 |
|------------------|---------|

|              |                          |
|--------------|--------------------------|
| <b>Image</b> | NRBGS_1.jpg, NRBGS_3.jpg |
|--------------|--------------------------|

