

This Drawing is the property of J.S.T.(U.K.) Ltd.
It must not be copied or used for manufacturing
without written permission from J.S.T.(U.K.) Ltd.

**UNCONTROLLED
CUSTOMER ISSUE**

Page 1 / 2


CS-48N003V0	48N003V0	PA66	UL94V-0	Natural	110	--	
4803-187 Red	48N303	PA66	UL94V-2	Red	110	E172855 (M)	
4803-187 Green	48N403	PA66	UL94V-2	Green	110	E172855 (M)	
4803-187 Black	48N503	PA66	UL94V-2	Black	110	E172855 (M)	
4803-187	48N003	PA66	UL94V-2	Natural	110	E172855 (M)	
JST Part Number	Mfg Number	Material	Flame Class	Colour	Max Operating Temp (°C)	UL Card No.	//

Revision Record		
	Add suffixes; 003V0	16.12.02
	Add suffixes; 003, 503, 403 & 303	16.12.02
	Modification Detail	Date
<i>JST</i>		

Part Description & General Details:		
Housing for 4.8 (.187) receptacle. Applicable JST terminal; STO-**(*)-187*(-*) Not suitable for STO-62(*)-187*(-*)		
Series:	48 Series	
Drawing Ref:	CS48N003-040794	
Issues by:	MR	16.12.02
Approved by:	AR	17.12.02

This Drawing is the property of J.S.T.(U.K.) Ltd.
It must not be copied or used for manufacturing
without written permission from J.S.T.(U.K.) Ltd.

**UNCONTROLLED
CUSTOMER ISSUE**

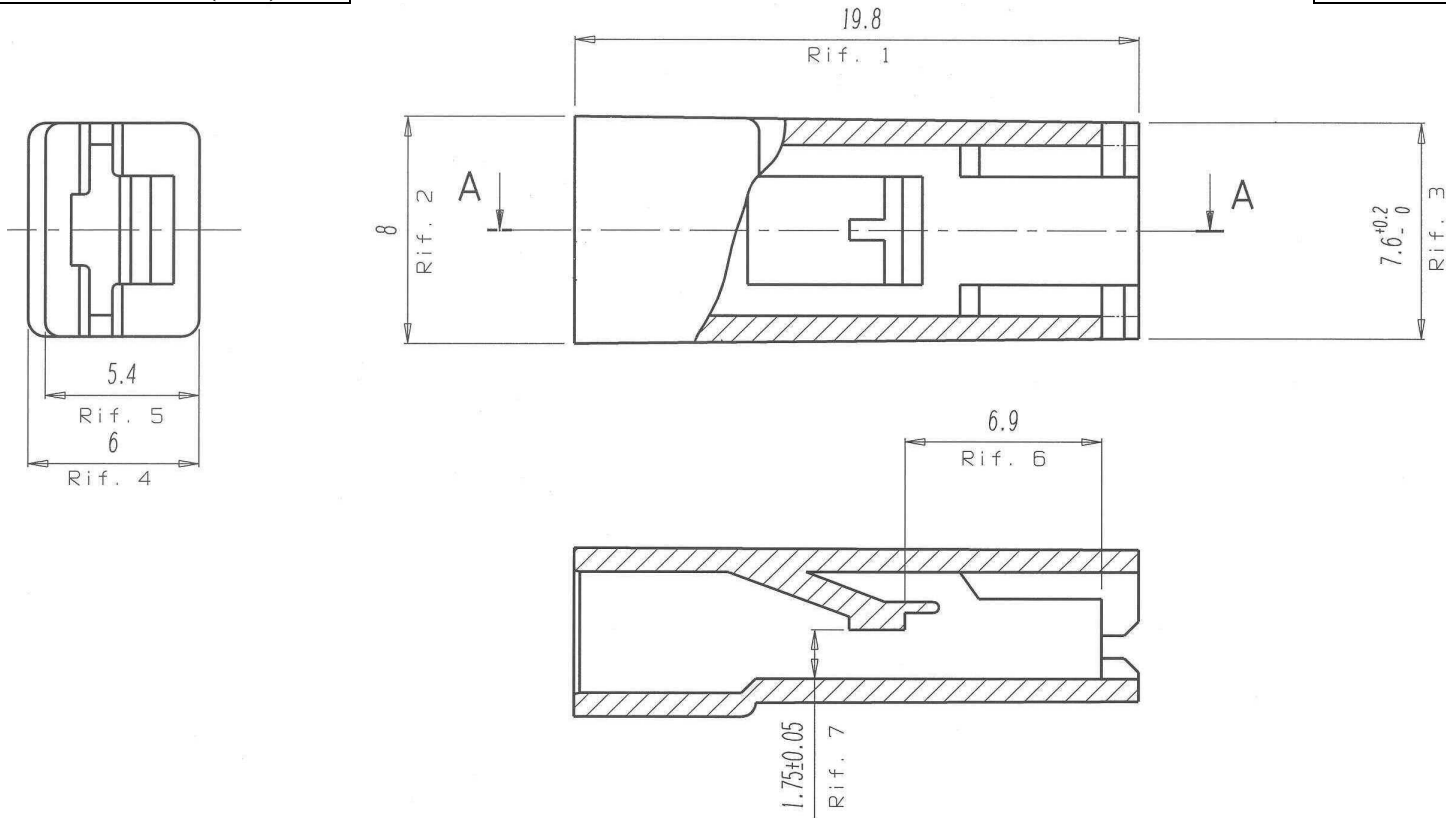

Revision Record		
	Add suffixes; 003, 503, 403 & 303	16.12.02
	Modification Detail	Date

JST

Part Description & General Details:		
Housing for 4.8 (.187) receptacle. Applicable JST terminal; STO-**(*)-187*(-*) Not suitable for STO-62(*)-187*(-*)		
Series:	48 Series	
Drawing Ref:	CS48N003-040794	
Issues by:	MR	16.12.02
Approved by:	AR	17.12.02