

SPECIFICATION SHEET

tactic Synchronous & Quartz



Panel mounting



<u>PRODUCT CODE*</u>	<u>DIAL TYPE</u>	<u>SWITCHING CAPACITY</u>
tactic 111.2	24 HOUR	16 Amps
tactic 171.2	7 DAY	16 Amps
tactic 211.2	24 HOUR	16 Amps
tactic 271.2	7 DAY	16 Amps

All products are suitable for panel mounting only. connection is made by use of 1/4" (6.3mm) tab terminal receptacle connectors (not provided). Quartz versions have 150 hour battery back-up.


***Product code key:**

- 1.. 1 = Synchronous without running reserve
- 2 = Quartz with running reserve
- 3-5 = Digital
- .1. 1 = Day program (24 hour)
- 7 = Week program (7 day)
- ..1 1 = 1-channel
- 2 = 2-channel
- ... 1 0 = Surface mounting
- 1 = Universal mounting
- 2 = Flush mounting

Technical specification:

Control panel cutout 68 x 68 mm
 Weight 160g
 AC switching capacity:
 - resistive load 16A 250v AC
 - inductive load cos ϕ 0.6 8A 250v AC
 - incandescent lamp load 1350W
 - fluorescent lamp load 60W
 Minimum switching current 100mA (20v) AC/DC
 Ambient temperature:
 - Synchronous units -20 °C to +85°C
 - Quartz units -20°C to +55°C
 Accuracy mains synchronized typ. \pm 2.5 sec. / day
 Battery charging time (quartz) 70 hours
 Minimum switching time:
 - 24 hour dials 15 minutes
 - 7 day dials 2 hours
 Manual override fix ON / timed / fix OFF

Optional working voltages:
 Tactic 211.2 / 271.2 only
 Standard options – 24v AC/DC; 110v AC
 On request (subject to availability) : 6 – 72v DC; 12 – 160v 45/60Hz

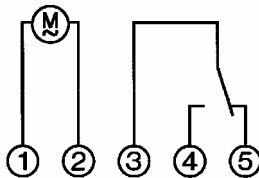

Tactic wiring