

GOP Boxes



GOP Boxes (MGOP2, MGOP4, MGOP6)

Our range of grid outlet position boxes and latch plates are ideal for fitting onto the end of a flexible conduit. These boxes allow the presentation of 6C size outlets in a vertical grid formation, providing both cable and outlet containment within raised floor systems. They are also ideal for attaching to the underside of desks in general office environments.

Features

- Available in 3 vertical grid layout options:- 2 outlets, 4 outlets and 6 outlets
- Keyed gland entry for either 25 or 32 mm flexible conduit
- Latch Plates optional - available in 25 and 32 mm sizes
- Cut out apertures are 6C (aka LJ6C) size
- 60 mm deep boxes to accommodate cable bend radius requirements
- Supplied and fitted with M6 screws for fast removal of the lid
- Suitable for use with our range of 6C fibre modules, Category 6/6A copper modules, keystone adaptors (for a wide range of connectors) and blanks
<http://www.tuk.co.uk/product/fibermod-angled-fibre-modules/>
<http://www.tuk.co.uk/product/category-6-6c-outlets-faceplates/>
<http://www.tuk.co.uk/product/keystone-angled-faceplate-adaptor-25-x-38-2/>

NOTE: GOP (Grid Outlet Position) boxes are also known as POD boxes by other manufacturers and suppliers.

Specifications

- Colour: black
- Material: Cold rolled steel
- Sizes:
 - 2 outlet 138 x 60 x 63 mm
 - 4 outlet 175 x 60 x 63 mm
 - 6 outlet 225 x 60 x 63 mm

Latch Plates



Latch Plates (MGOPLP25, MGOPLP32)

Our two Latch Plates are designed to accommodate flexible conduit during the fixing of GOP boxes into a raised floor box or in a workplace (such as under desk).

Features





- Fixing brackets for conduit used with GOP Boxes
- Available with apertures for 25 mm or 32 mm conduit
- Attractive semi-gloss finish matches our GOP boxes

Specifications


- Dimensions: 67.5 x 50 x 50 mm
- Weight: 56g
- Colour: Black
- Material: Cold rolled steel

ROHS Compliant

Code: MGOP2

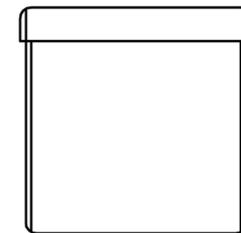
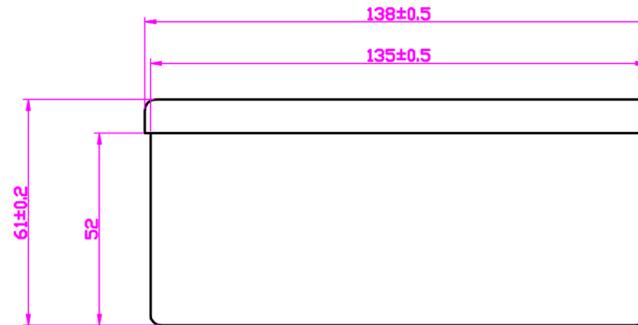
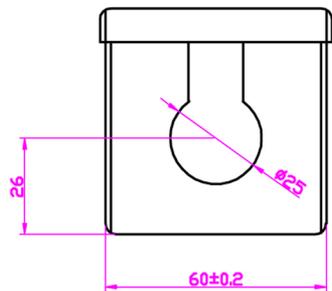
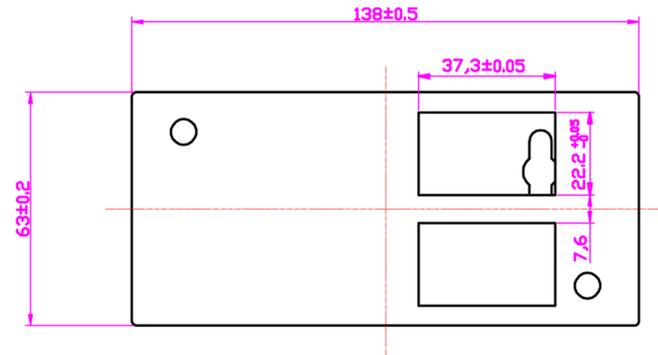


Cold-rolled steel sheets: 1.5mm

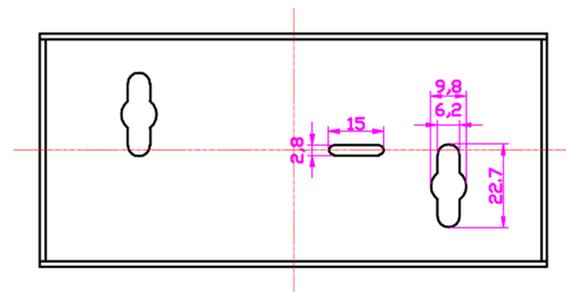


ROHS Compliant

Code: MGOP4

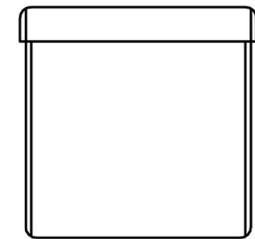
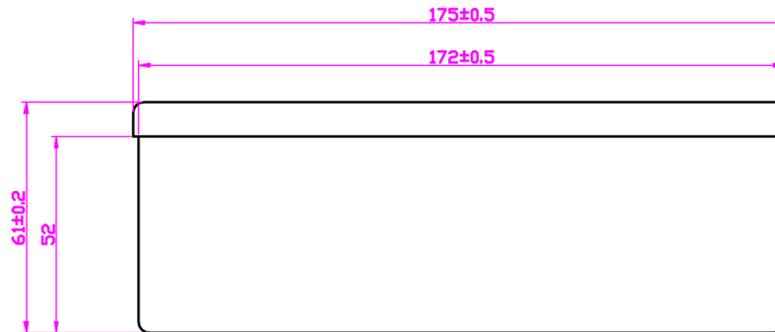
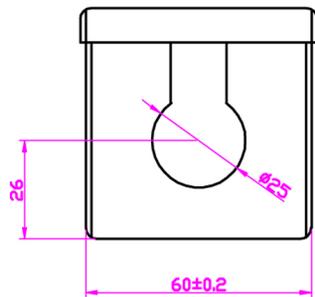
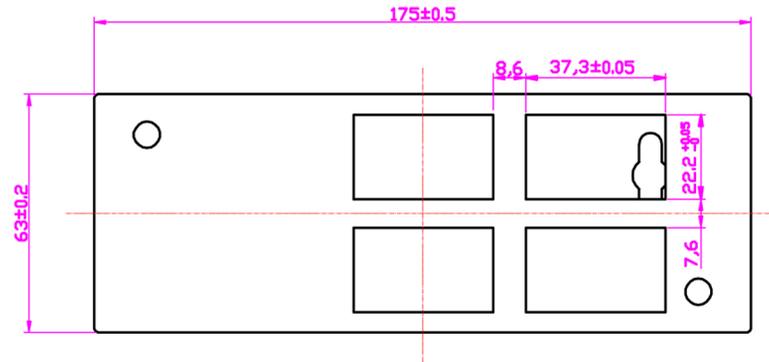


Cold-rolled steel sheets: 1.5mm

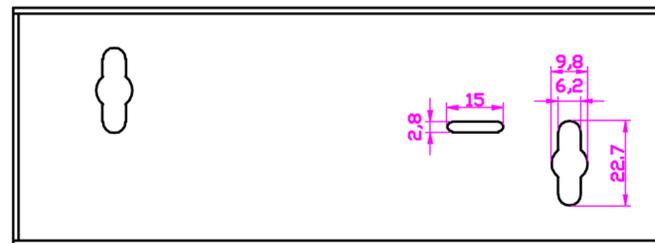


ROHS Compliant

Code: MGOP6

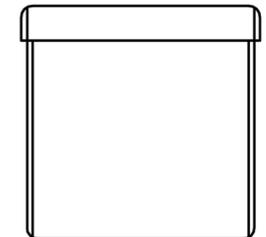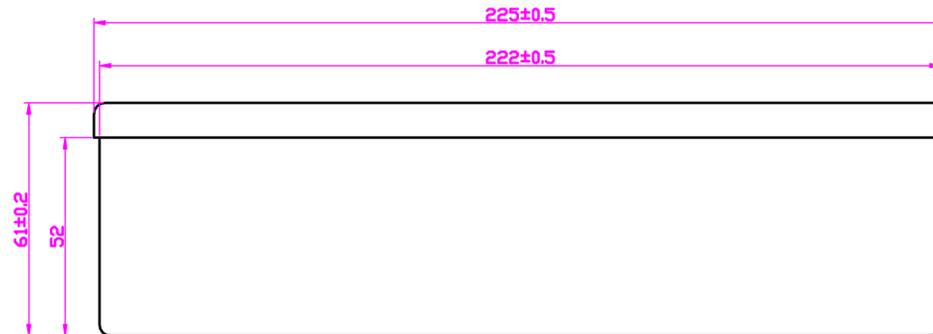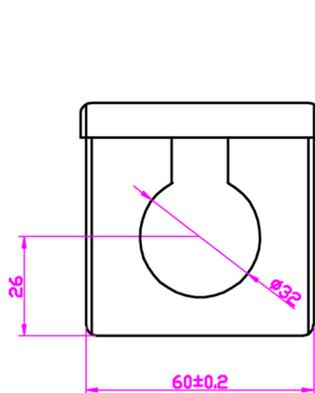
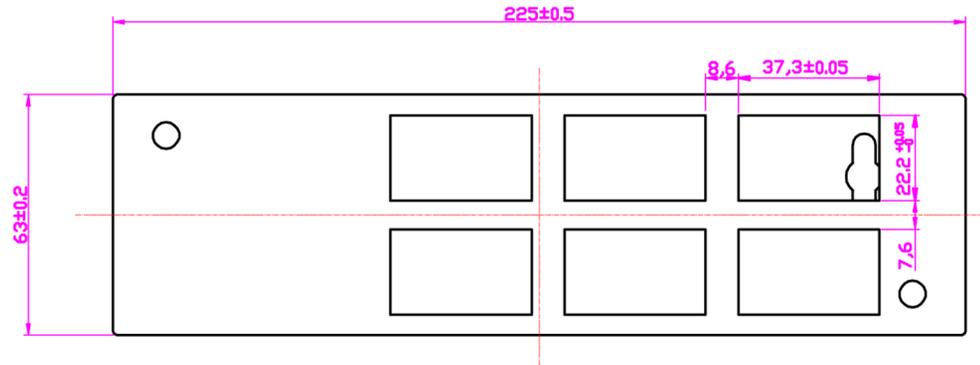


Cold-rolled steel sheets: 1.5mm

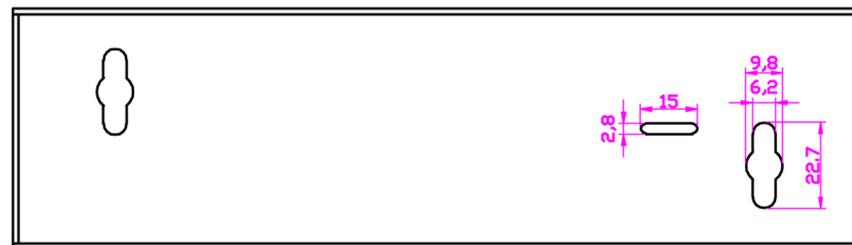

ROHS Compliant

Code: **MGOPLP32**
MGOPLP25

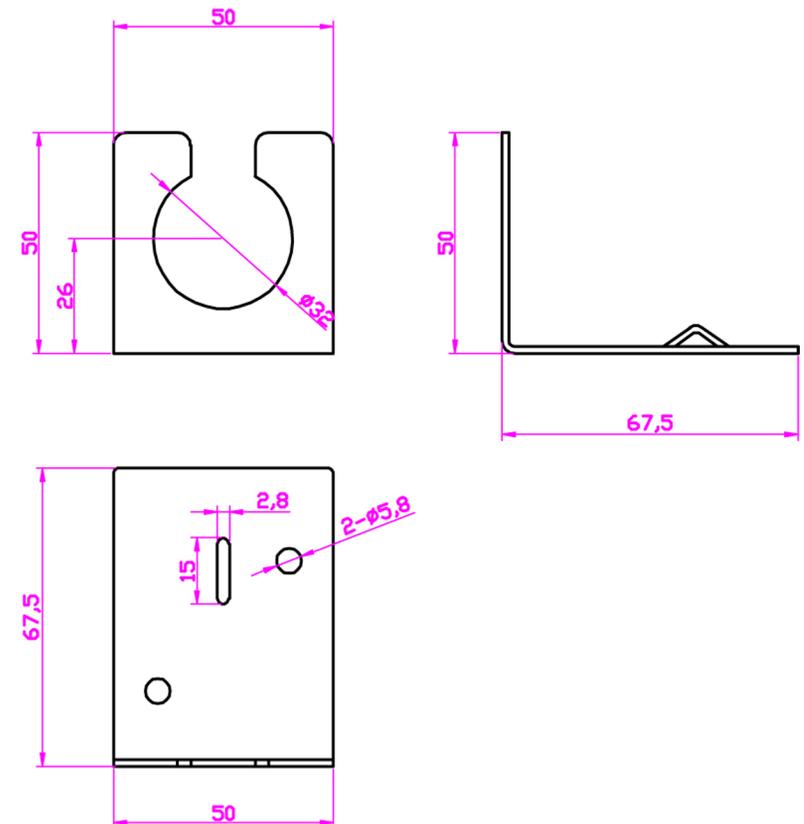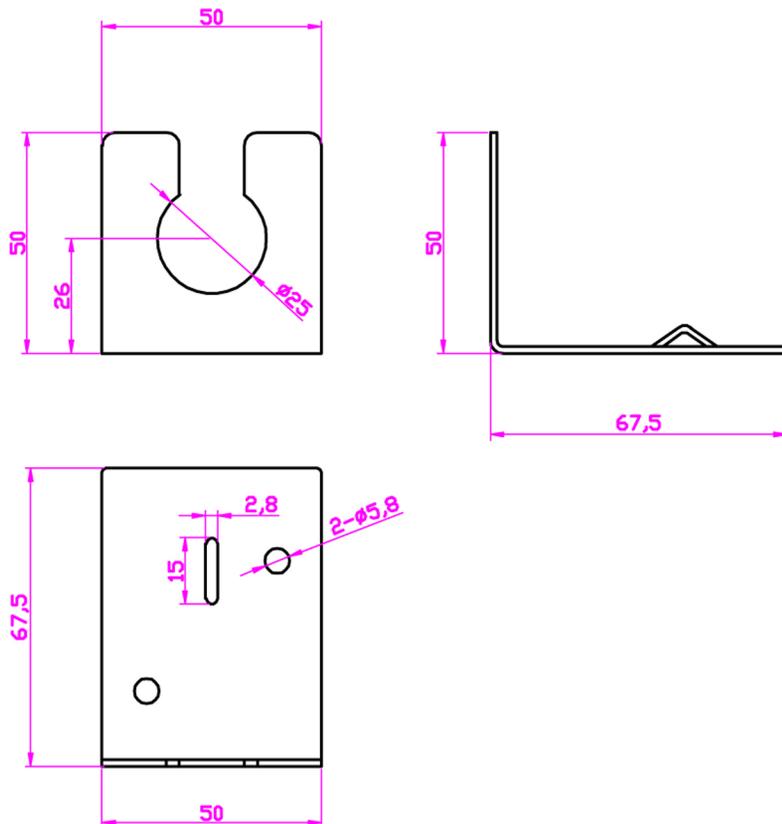

Cold-rolled steel sheets: 1.5mm