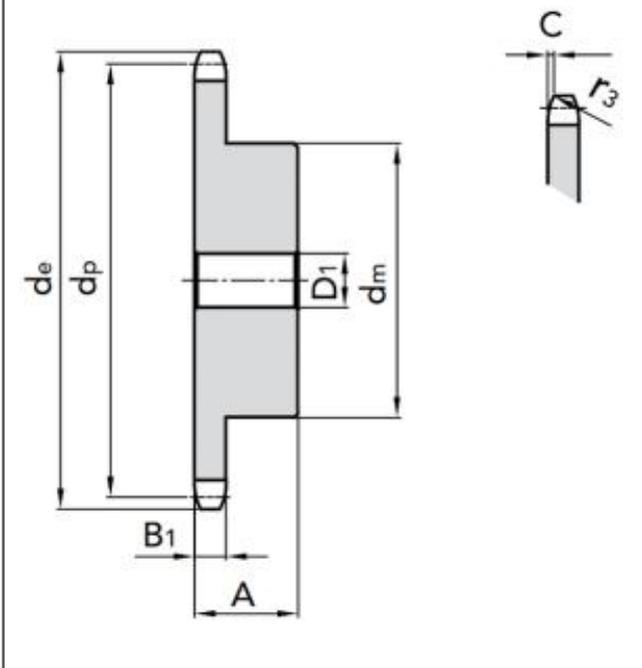


**10125014**

1in x 17.02 mm - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	14
de (DE) mm	125.27
dp (DP) mm	114.15
Part number (CODE)	10125014
dm (DM) mm	84
D1 (D1) mm	16
A (A) mm	40
Tooth radius r3 (R3) mm	26
Radius width C (C) mm	2.5
Sprockets tooth width B1 (B1) mm	16.2
Weight (WEIGHT) kg	2.08
Material (MAT)	STEEL C 45